



Product designation	Fuse 14x85mm
Product type designation	FE
Operating voltage type	DC

Electrical features

IEC maximum rated current (In)	A	25
IEC maximum rated voltage (Un)	V	1500
Rated current (In)	A	25
IEC fuse class		gPV
Power consumption at 0,7 In	W	2.5
Power consumption at In	W	6.4
Prearcing I2t	A2s	140
Total I2t at 1000Vdc	A2s	458


Ambient conditions

Operating temperature	min	°C	-20
	max	°C	+70
Storage temperature	min	°C	-40
	max	°C	+80
Max altitude	m		3000

Mechanical features

Weight	g	31
--------	---	----

Dimensions

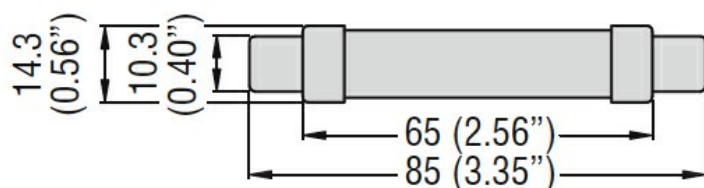

Certifications and compliance

Compliance	IEC/EN/BS 60269-6
------------	-------------------

ETIM classification

ETIM 8.0	EC002704 - Cylindrical fuse
----------	--------------------------------