




Number of poles	Nr.	1
Operating voltage type		AC
Contact characteristics		
IEC Conventional free air thermal current Ith	A	40
Mechanical features		
Tightening torque for terminals	min	Nm 1.8
	max	Nm 2
	min	Ibin 16
	max	Ibin 18

Dimensions

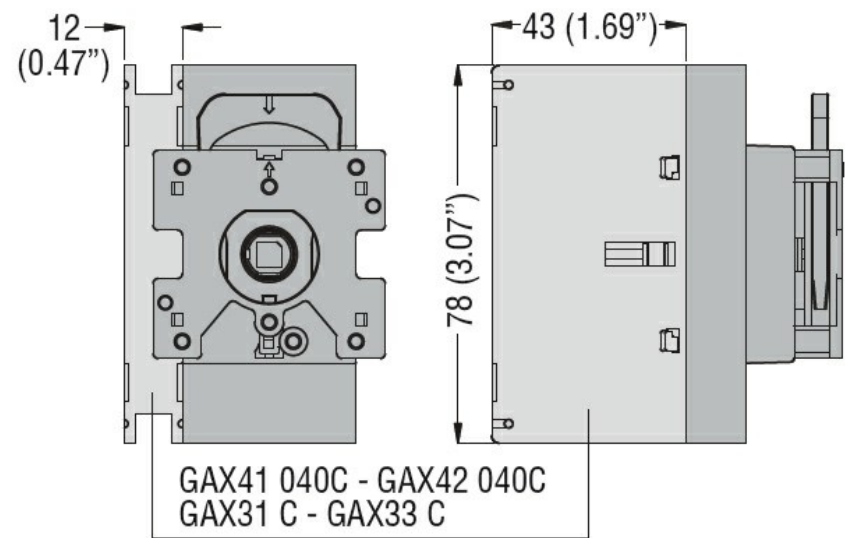

Wiring diagrams



Certifications and compliance

Compliance	CSA C22.2
	IEC/EN 60947-1
	IEC/EN 60947-3

Certifications	UL508
	UL98
	CCC
	CSA C22.2 n°14
	cULus according to UL508
	EAC

ETIM classification

ETIM 8.0

EC002498 -
Accessories/spare
parts for low-
voltage switch
technology