





Number of poles	Nr.	1	
Operating voltage type		AC	
Contact characteristics			
IEC Conventional free air thermal current Ith	A	40	
Mechanical features			
Tightening torque for terminals			
	min	Nm	1.8
	max	Nm	2
	min	Ibin	16
	max	Ibin	18

Dimensions

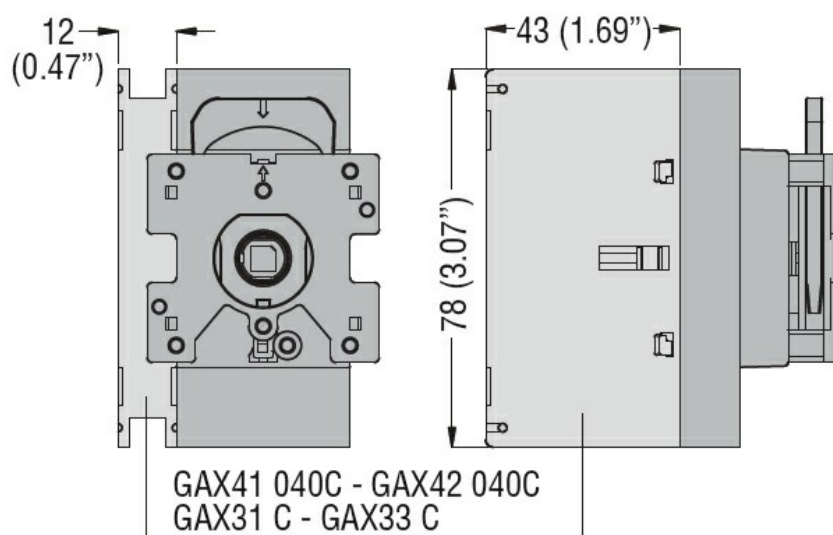

Wiring diagrams

Fourth pole add on
GAX42... GAX41...

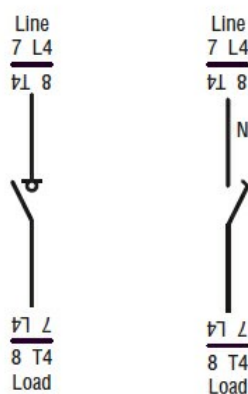

Certifications and compliance

Compliance

CSA C22.2
IEC/EN 60947-1
IEC/EN 60947-3
UL508
UL98

Certifications

CCC
CSA C22.2 n°14
cULus according to UL508
EAC

ETIM classification

ETIM 8.0

EC002498 -
Accessories/spare
parts for low-
voltage switch
technology