



Product designation

SOCKET

Product type designation

HR5XS21S

Contact characteristics

Rated insulation voltage U_i IEC/EN	V	250
Rated impulse withstand voltage U_{imp}	kV	4

Mechanical features

Socket screw tightening tool (cross / flat blade)	Phillips 1/4.5mm
---	------------------

Conductor section

AWG/Kcmil

min 20

max 14

IEC


min mm^2 0.5

max mm^2 2.5

Fixing

On 35mm DIN
rail


Dimensions

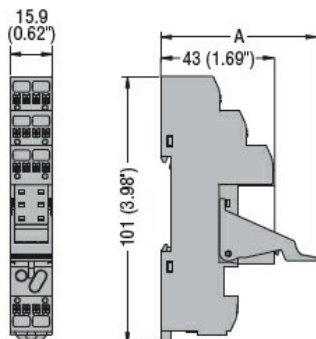

A: 60mm (2.36") with HR3X88

70mm (2.75") with XR5X88

Wiring diagrams

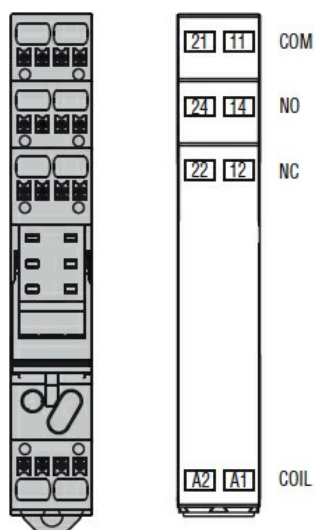

Certifications and compliance

Compliance

IEC/EN 61810

Certificates

CSA

cURus

EAC

ETIM classification

ETIM 8.0

EC001456 -
Relay socket