



Product designation  
Product type designation

SOCKET  
HR7XS2

#### Contact characteristics

Rated insulation voltage $U_i$ IEC/EN	V	250
Rated impulse withstand voltage $U_{imp}$	kV	4

#### Mechanical features

Socket screw tightening tool (cross / flat blade)	Phillips 1/4.5mm
---	------------------

Conductor section

AWG/Kcmil

min	20
max	14


IEC

min	mm <sup>2</sup>	0.5
max	mm <sup>2</sup>	2.5



Fixing

On 35mm DIN  
rail and with  
screw

#### Dimensions

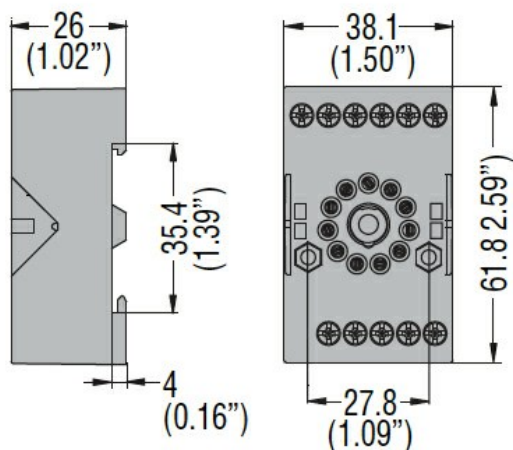

#### Wiring diagrams

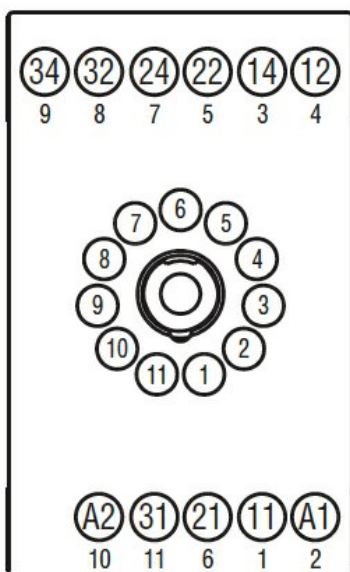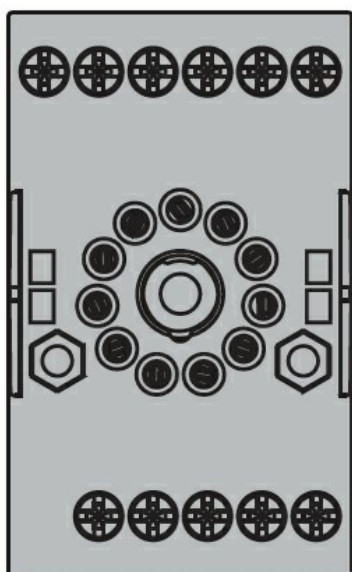

## Certifications and compliance

### Compliance

IEC/EN 61810

### Certificates

CSA

cURus

EAC

## ETIM classification

ETIM 8.0

EC001456 -  
Relay socket