



Product designation

Product type designation

Test elements for
steady-light LED
elements
LPXT

Operations

Electrical life hours 100000

Mechanical features

Tightening torque for terminals max Nm 1

Conductor section

AWG/kcmil conductor section

max 12

IEC

max mm² 1 or 2 / 2.5

Mounting adapter

LPXAU120

Weight

g 11

Ambient conditions

Temperature


Operating temperature

min °C -25
max °C +70


Storage temperature

min °C -40
max °C +85

Dimensions

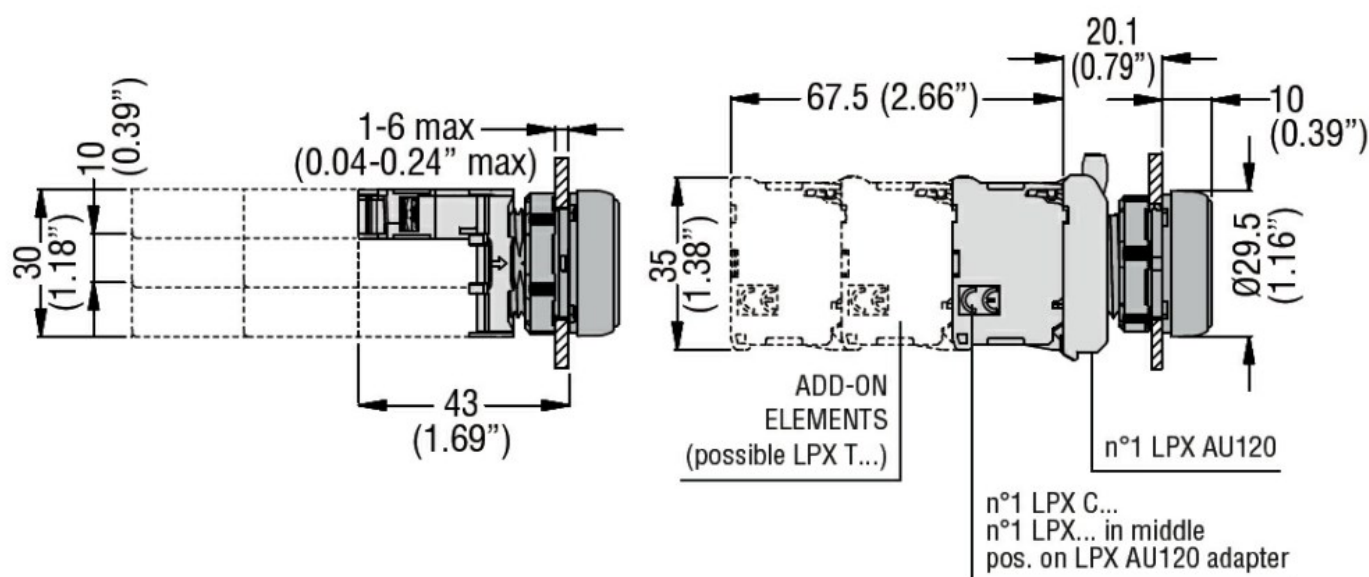

Wiring diagrams

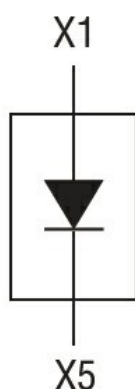

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN/BS 60947-1

IEC/EN/BS 60947-5-1

UL508

Certificates

CCC

cULus

EAC

RINA

ETIM classification

ETIM 8.0

EC002498 -
 Accessories/spare
 parts for low-
 voltage switch
 technology