



Product designation

Product type designation

Number of poles

Number of DIN modules

Compliance

Add-on blocks  
and accessories  
- 1 changeover  
contact  
P1X1311  
1 C/O  
0.5  
IEC/EN/BS  
60947-5-1

#### Electrical features

Rated impulse withstand voltage Uimp	kV	4
Rated operational voltage AC (IEC)	VAC	400
Rated current (In)	A	6
Conductivity		12V 10mA


#### Ambient conditions

Operating temperature	min	°C	-40
	max	°C	+70
Storage temperature	min	°C	-40
	max	°C	+80


#### Mechanical features

Operating position	normal allowable		Vertical plan Any
Tightening torque for terminals	min	Nm	1
	max	Nm	1
	min	lbin	0.7
	max	lbin	0.7
Terminals tool	PH2		
Conductor section	IEC		
	max	mm²	1x 2.5 - 2x 1.5
Weight	g		40

#### Dimensions

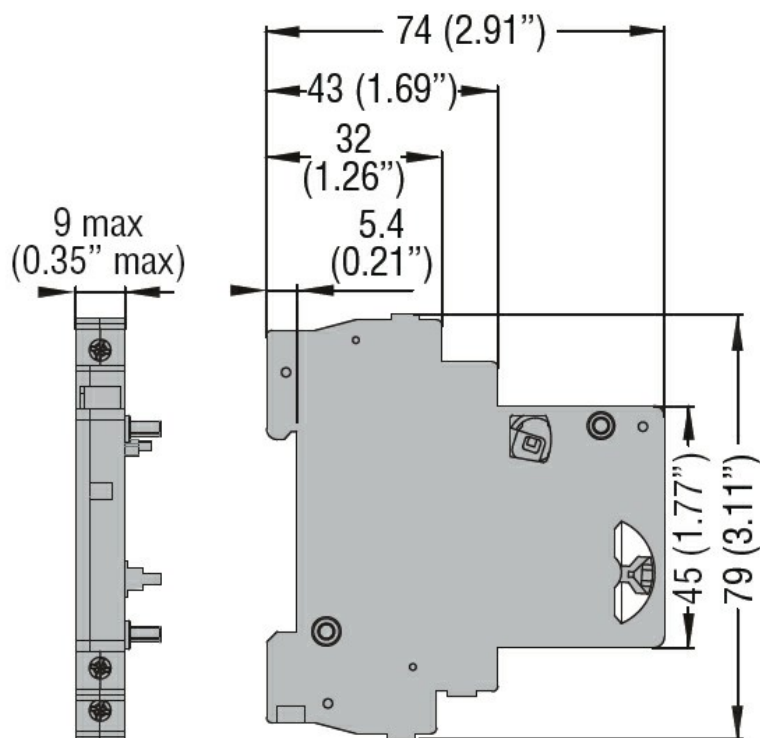

#### Wiring diagrams

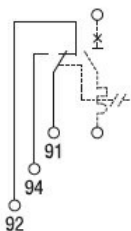

#### Certifications and compliance

##### Compliance

IEC/EN 60947-5-1.

##### Certifications

EAC

#### ETIM classification

ETIM 8.0

EC000041 -  
Auxiliary contact  
block