




| | | |
|---|-----|---------|
| Number of poles | Nr. | 1 |
| Operating voltage type | | AC |
| Contact characteristics | | |
| IEC Conventional free air thermal current Ith | A | 40 |
| Mechanical features | | |
| Tightening torque for terminals | min | Nm 1.8 |
| | max | Nm 2 |
| | min | Ibin 16 |
| | max | Ibin 18 |

Dimensions

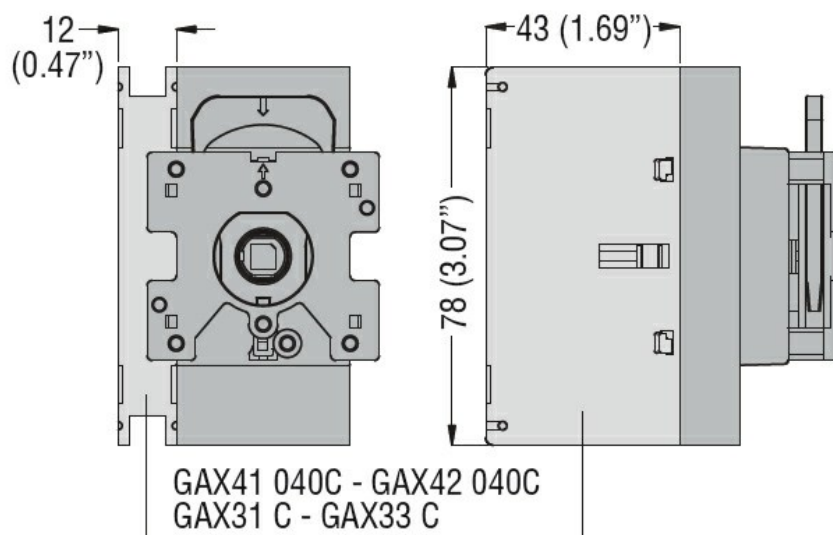

Wiring diagrams



Certifications and compliance

| | |
|------------|----------------|
| Compliance | CSA C22.2 |
| | IEC/EN 60947-1 |
| | IEC/EN 60947-3 |

| | |
|---------------------|---|
| | UL508 |
| | UL98 |
| Certifications | CCC |
| | CSA C22.2 n°14 |
| | cULus according to UL508 |
| | EAC |
| ETIM classification | |
| ETIM 8.0 | EC002498 - Accessories/spare parts for low- voltage switch technology |