



Handles for  
switch  
disconnecter  
GAX6

## Product designation

## Product type designation

## Mechanical features

Weight g 73

## UL technical data

UL Standard UL60947-4-1

## Ambient conditions

## Operating temperature

min	°C	-25
max	°C	+55

## Storage temperature

min	°C	-40
max	°C	+70

## Max altitude


m	3000
---	------

## Resistance & Protection

Frontal IP degree IP65

Pollution degree 3

## Dimensions

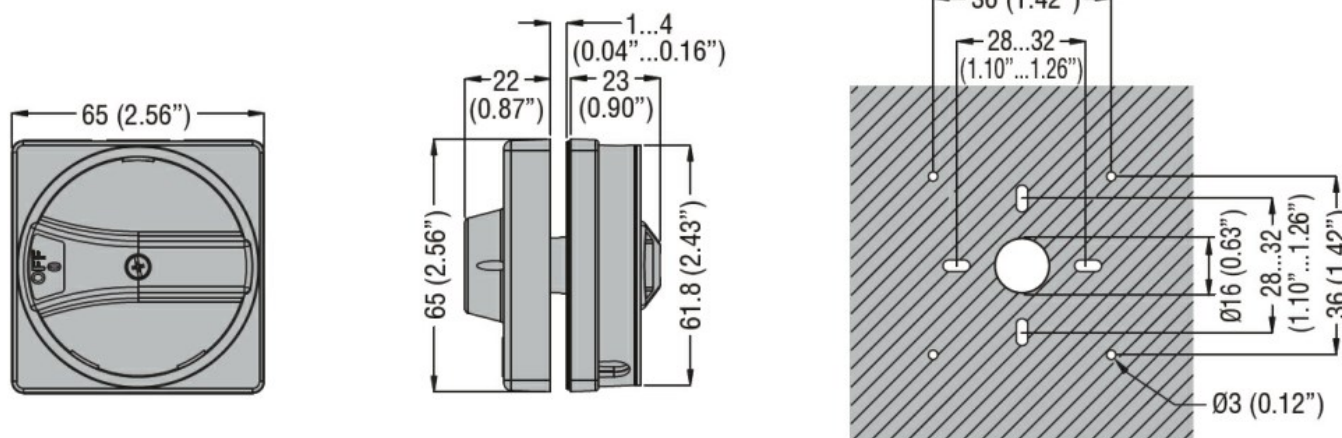

## Certifications and compliance

## Compliance

CSA C22.2

IEC/EN 60947-1

IEC/EN 60947-3

UL508

UL98

## Certifications

cULus according to UL508 /CSA C22.2 n°14

cULus according to UL98 / CSA C22.2 n°4

EAC

ETIM classification

ETIM 8.0

EC000230 -  
Door coupling  
handle for  
switchgear