




Product designation	Empty enclosures		
Product type designation	M24N		
Electrical features			
Maximum operating current (≤440V)	A	38	
Components			
Contactor standard supplied	BG.../BF09A... BF25A		
Mechanical features			
Weight	g	625	
Ambient conditions			
Operating temperature	min	°C	-25
	max	°C	+60
Storage temperature	min	°C	-40
	max	°C	+70
Resistance & Protection			
Frontal IP degree	IP65		
Dimensions			

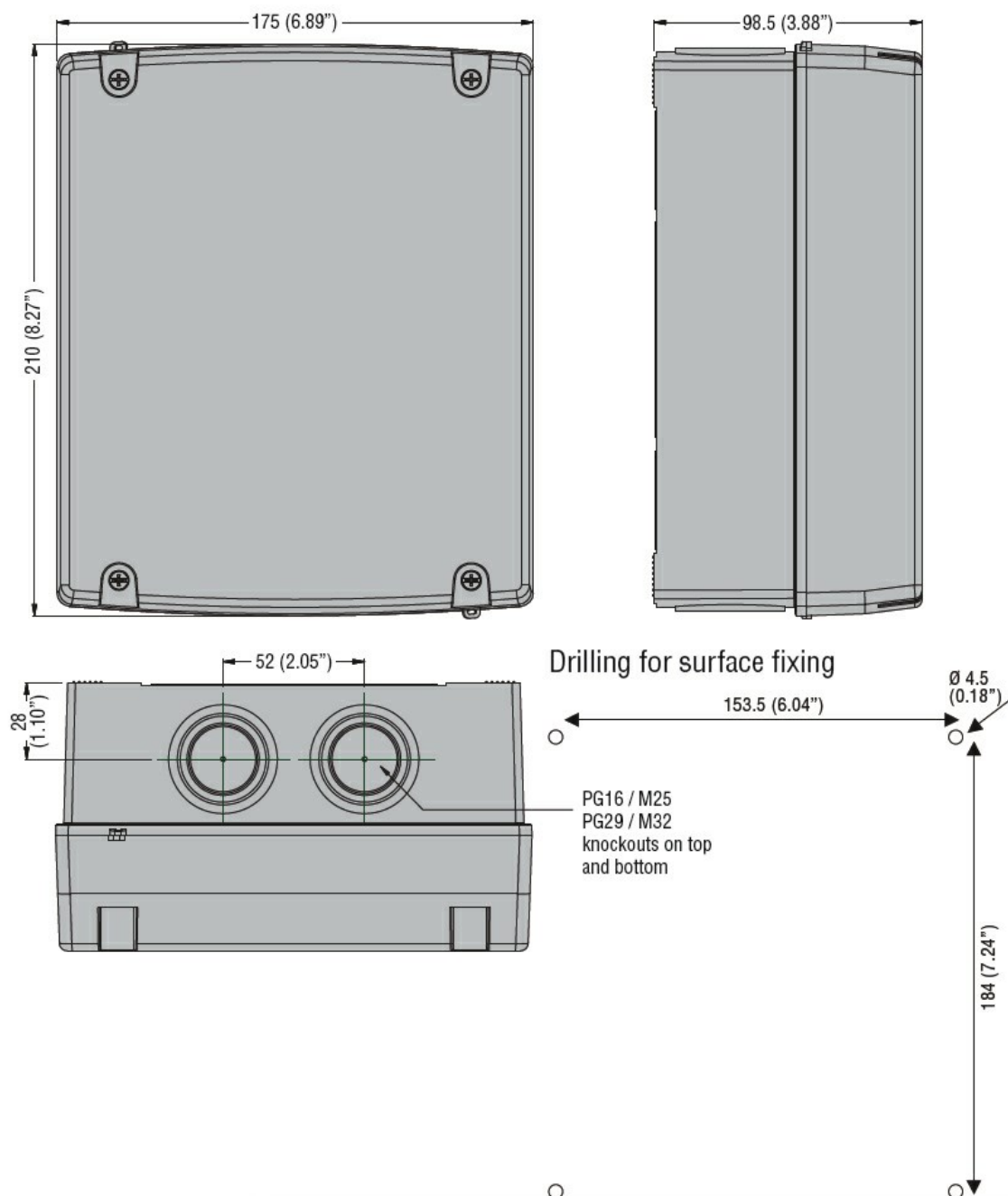

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-4-1

UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices