



Product designation
Product type designation

Probe
CGL125

Connections

Terminals type

Threaded rod
with nut

Ambient conditions

Temperature

Operating temperature

max °C +180

Maximum operating pressure


bar 10

Housing

Weight

g 281

Dimensions

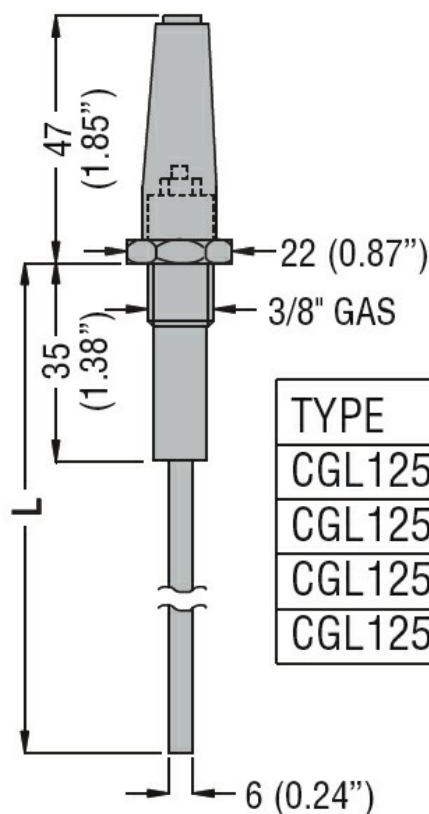

| TYPE | L |
|-----------|---------------|
| CGL125 3 | 327 (12.87") |
| CGL125 5 | 500 (19.68") |
| CGL125 7 | 700 (27.56") |
| CGL125 10 | 1000 (39.37") |

Certifications and compliance

Compliance

/

Certificates

EAC

ETIM classification

ETIM 8.0

EC010106 -
Liquid level
sensor