



Product designation  
Product type designation

Probe  
CGL125

#### Connections

Terminals type

Threaded rod  
with nut

#### Ambient conditions

Temperature

Operating temperature

max °C +180

Maximum operating pressure


bar 10

#### Housing

Weight

g 126

#### Dimensions

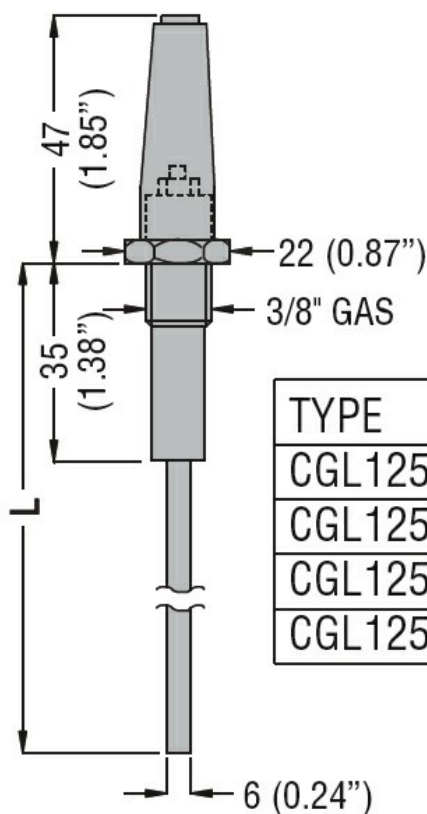

TYPE	L
CGL125 3	327 (12.87")
CGL125 5	500 (19.68")
CGL125 7	700 (27.56")
CGL125 10	1000 (39.37")

#### Certifications and compliance

Compliance

/

Certificates

EAC

#### ETIM classification

ETIM 8.0

EC010106 -  
Liquid level  
sensor