



Product designation	Probe
Product type designation	SCM

Connections

Terminals type	Threaded rod with nut
----------------	-----------------------


Ambient conditions

Temperature	Operating temperature	max	°C	+100
Maximum operating pressure		bar		10

Housing

Weight	g	162
--------	---	-----

Dimensions

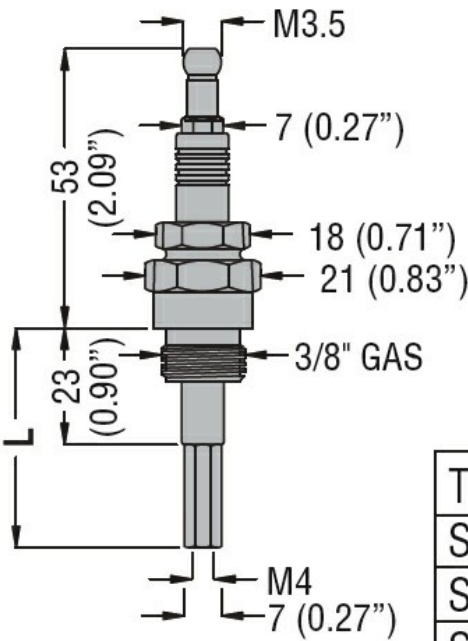

TYPE	L
SCM04	43 (1.69'')
SCM50	500 (19.68'')
SCM100	1000 (39.37'')

Certifications and compliance

Compliance	/
------------	---

Certificates	EAC
--------------	-----

ETIM classification

ETIM 8.0	EC010106 - Liquid level sensor
----------	--------------------------------