





Product designation			Signal tower	
Product type designation			Ø45mm/1.7"	
8TL4				
General characteristics				
Diameter		mm - inch		45 / 1.77
Supply voltage (DC)		V		24±10%
Colour		Green, red		
IEC degree of protection		IP54		
Light consumption per module (DC)		mA		37
Mechanical features				
Tightening torque for terminals max		Nm		0.5
Terminals screw		Screw clamp terminals		
Conductor section				
AWG/Kcmil				
		max		16
IEC				
		max		mm²
				1.5
Weight		g		160
Ambient conditions				
Temperature				
Operating temperature				
		min		°C
		max		°C
				-20
				+50
Dimensions				

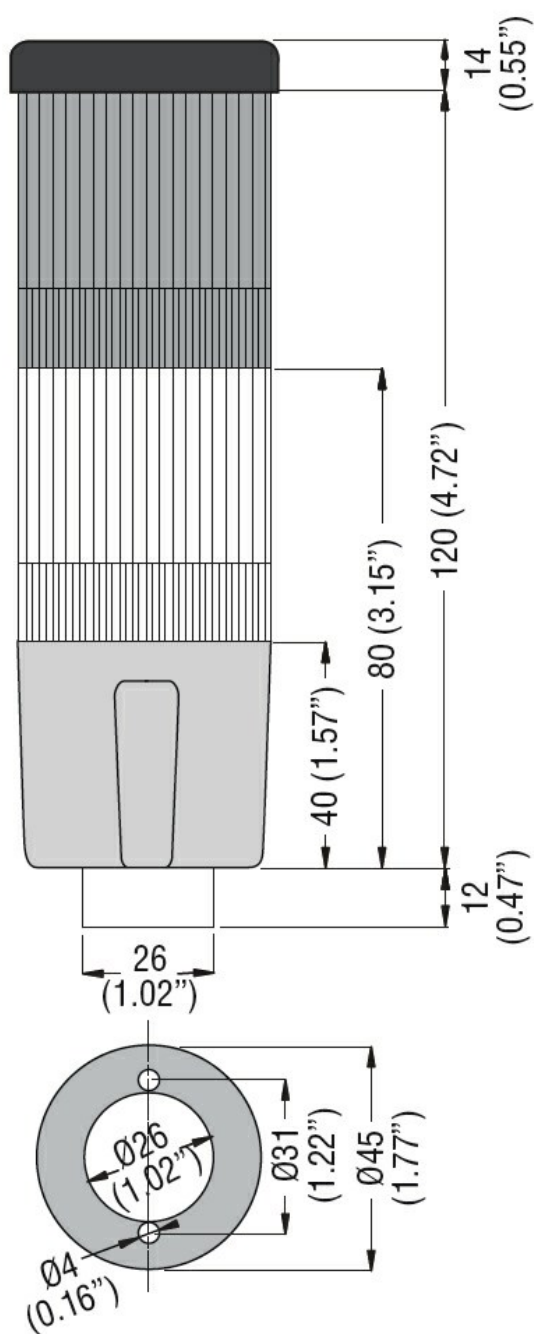

Wiring diagrams

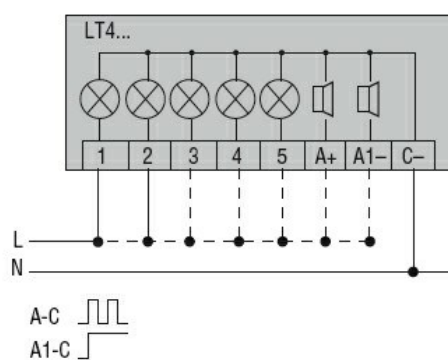

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN 60947-1
IEC/EN 60947-5-1
UL508

Certificates

cULus
EAC

ETIM classification

ETIM 8.0

EC001042 -
Signal tower
complete