





Product designation			Signal tower		
Product type designation			Ø45mm/1.7"		
8TL4					
General characteristics					
Diameter			mm - inch	45 / 1.77	
Supply voltage (DC)			V	24±10%	
Colour			Green, orange, red		
IEC degree of protection			IP54		
Light consumption per module (DC)			mA	37	
Mechanical features					
Tightening torque for terminals max			Nm	0.5	
Terminals screw			Screw clamp terminals		
Conductor section					
AWG/Kcmil		max		16	
IEC		max		mm²	1.5
Weight			g	240	
Ambient conditions					
Temperature					
Operating temperature			min	°C	-20
			max	°C	+50
Dimensions					

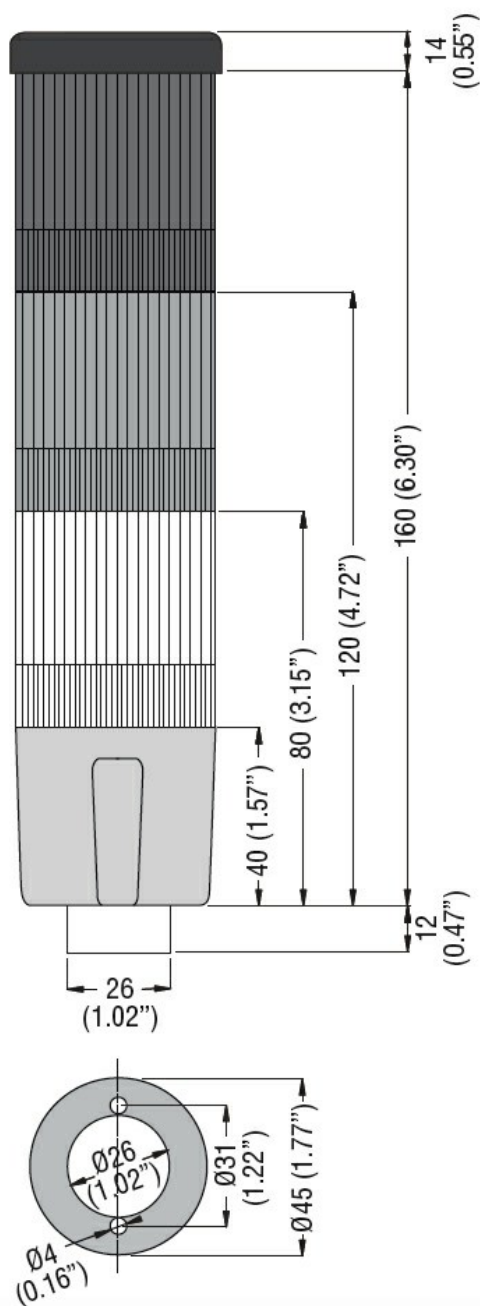

Wiring diagrams

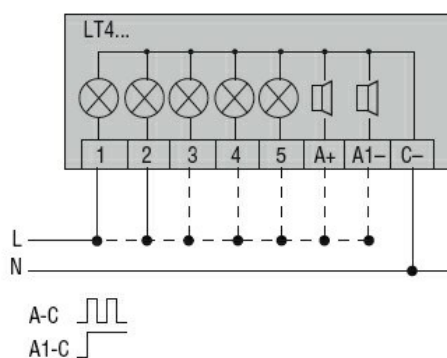

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN 60947-1
IEC/EN 60947-5-1
UL508

Certificates

cULus
EAC

ETIM classification

ETIM 8.0

EC001042 -
Signal tower
complete