





Product designation			Signal tower	
Product type designation			Ø45mm/1.7"	
8TL4				
General characteristics				
Diameter		mm - inch	45 / 1.77	
Supply voltage (DC)		V	24±10%	
Colour			Green, orange, red	
IEC degree of protection			IP54	
Light consumption per module (DC)		mA	37	
Sound module consumption (DC)		mA	15	
Sound intensity		dB	80	
Mechanical features				
Tightening torque for terminals max		Nm	0.5	
Terminals screw			Screw clamp terminals	
Conductor section				
	AWG/Kcmil			
		max	16	
	IEC			
		max	mm²	1.5
Weight			g	320
Ambient conditions				
Temperature				
	Operating temperature			
		min	°C	-20
		max	°C	+50
Dimensions				

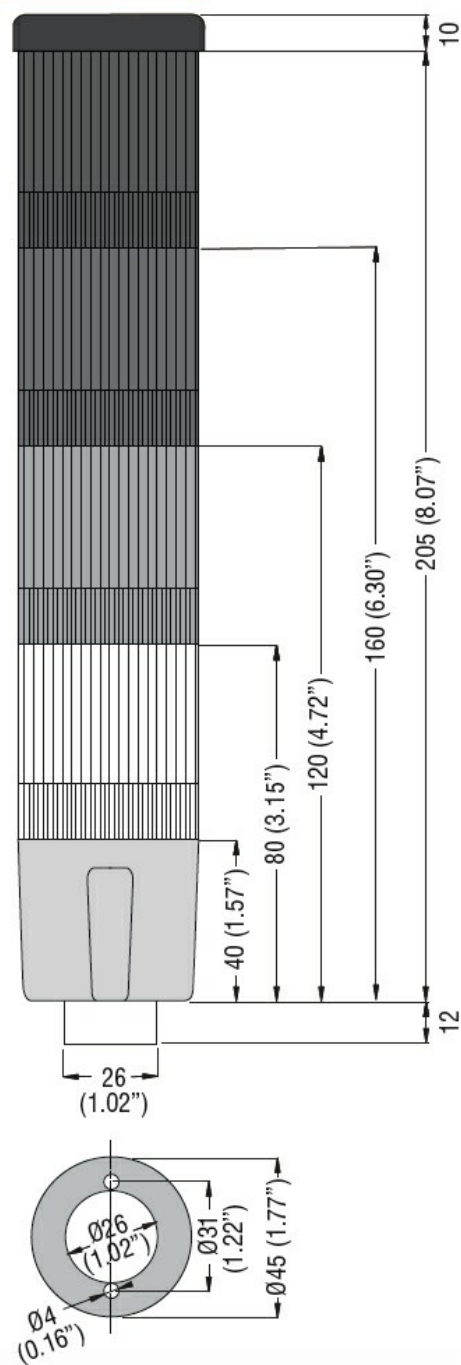

## Wiring diagrams

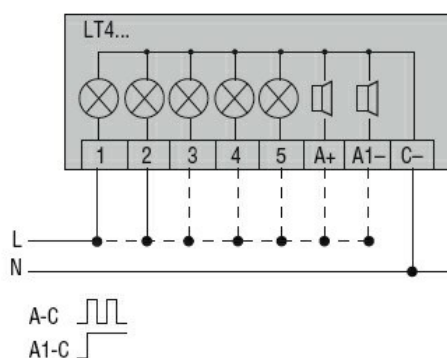

## Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC001042 -  
Signal tower  
complete