





Product designation				Signal tower
Product type designation				Ø45mm/1.7"
8TL4				
General characteristics				
Diameter			mm - inch	45 / 1.77
Supply voltage (DC)			V	24±10%
Colour			White, green, blue, orange, red	
IEC degree of protection			IP54	
Light consumption per module (DC)			mA	37
Mechanical features				
Tightening torque for terminals max			Nm	0.5
Terminals screw			Screw clamp terminals	
Conductor section				
AWG/Kcmil		max	16	
IEC		max	mm²	1.5
Weight			g	400
Ambient conditions				
Temperature				
Operating temperature			min	°C
			max	°C
-20				
+50				
Dimensions				

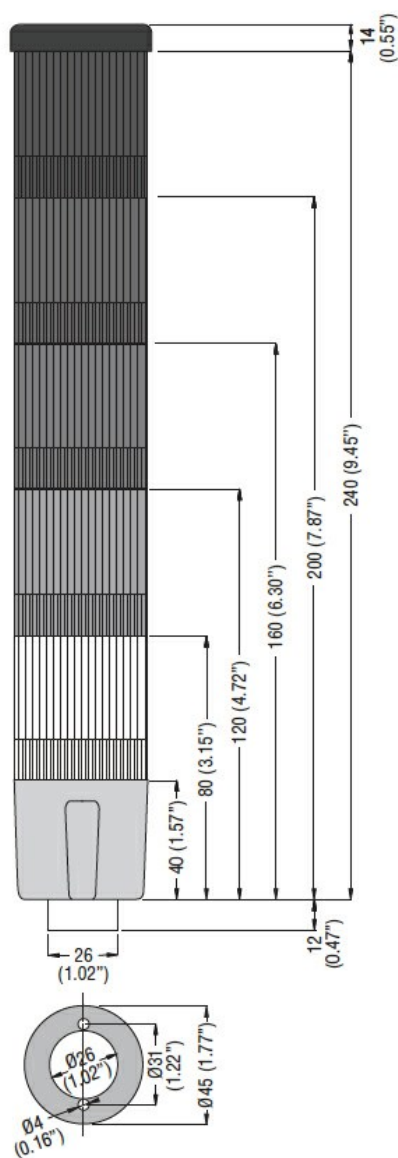

## Wiring diagrams

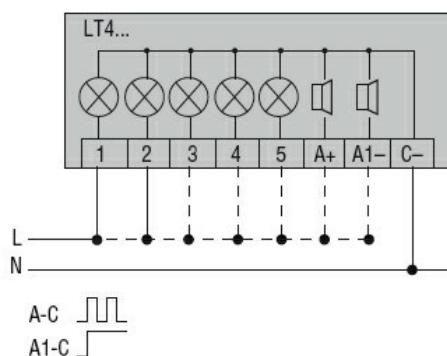

## Certifications and compliance

### Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

### Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC001042 -  
Signal tower  
complete