



Product designation

Product type designation

Signal tower
Ø70mm/2.75"
8LT7C -
Connection
modules

General characteristics

Diameter	mm - inch	70 / 2.75
Colour		Black
IEC degree of protection		IP65

Mechanical features


Tightening torque for terminals max	Nm	0.5
Terminals screw		Screw clamp terminals

Conductor section	AWG/Kcmil			
		max		16
	IEC			
		max	mm ²	1.5
Weight			g	110


Ambient conditions

Temperature	Operating temperature			
		min	°C	-20
		max	°C	+50

Dimensions

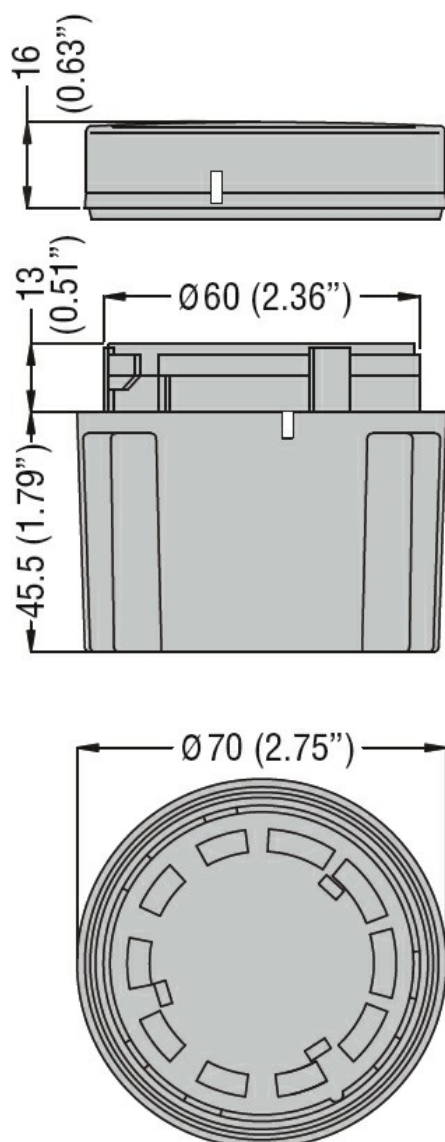

Wiring diagrams

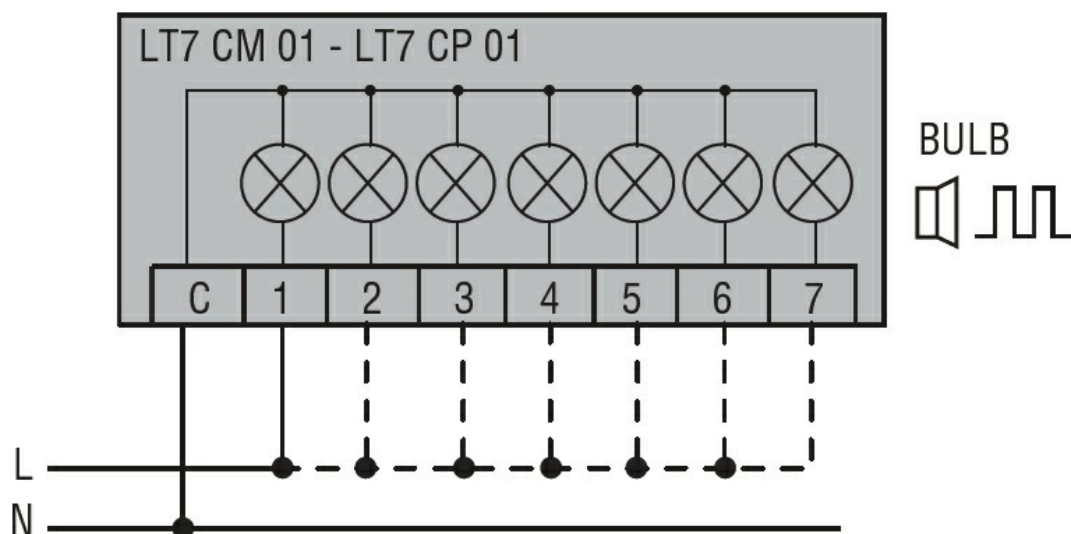

Connect terminals C and 1 as indicated to power the first module.
If other modules are fitted, the respective terminals must be
connected accordingly.

Certifications and compliance

Compliance

CSA C22.2 n°14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC001152 -
Connection
module for signal
tower