




Product designation			Bus module for EASY BRANCH	
Product type designation			EXS0000	
Auxiliary supply Us				
Auxiliary rated supply voltage DC			VDC	24
Auxiliary operating voltage range DC			min	VDC 20.4
			Max	VDC 27.6
Power dissipation Max			W	5.5
Mechanical features				
Housing type			Polyamide	
Terminals type			Screw	
Conductor cross section			min	mm² 0.2
			Max	mm² 2.5
			min	AWG 12
			Max	AWG 24
Tightening torque (Max)			Nm	0.5
			lbin	4.5
Weight			g	90
Ambient conditions				
Temperature				
			Operating temperature	
			min	°C -20
			max	°C +60
Storage temperature				
			min	°C -30
			max	°C +80
Relative humidity			%	<80
Maximum Pollution degree			2	
Overvoltage category			3	
Protection degree			IP20	
Dimensions				

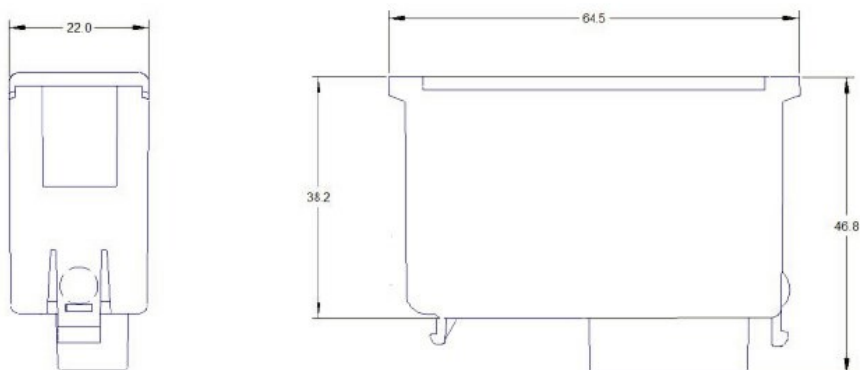

Certifications and compliance

Compliance	
	IEC/EN/BS 61000-6-2
	IEC/EN/BS 61000-6-4
	IEC/EN/BS 61010-1
Certificates	
	CE
	EAC
	UKCA