



USB interface,
A/A female type
connection
LPCD0

Product designation

Product type designation

General characteristics

Material	Polyamide
IEC degree of protection	IP65 on front and IP20 on rear

Electrical characteristics

Rated insulation voltage Ui IEC/EN	V	5VAC/DC
Contact resistance	mΩ	≤30

Mechanical features

Weight	g	18
--------	---	----

UL technical data

UL degree of protection	1, 2, 3R, 4, 4X, 12, 12K on front
-------------------------	--------------------------------------

Ambient conditions

Temperature


Operating temperature

min	°C	-25
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+85

Dimensions

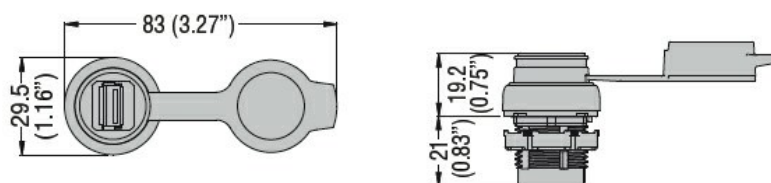

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN/BS 60947-1
IEC/EN/BS 60947-5-1
UL508

Certificates

cULus
EAC

ETIM classification

ETIM 8.0

EC000797 -
USB-Hub