



Product designation

Empty
enclosures

Product type designation

M0PA

Electrical features

Maximum operating current ($\leq 440V$) A 12

Components

Contactor standard supplied BG06, BG09, BG12

Thermal relay to purchase separately RF9

Mechanical features

Weight g 490

Ambient conditions


Operating temperature	min	°C	-25
	max	°C	+60

Storage temperature	min	°C	-40
	max	°C	+70


Resistance & Protection

Frontal IP degree IP65

Dimensions

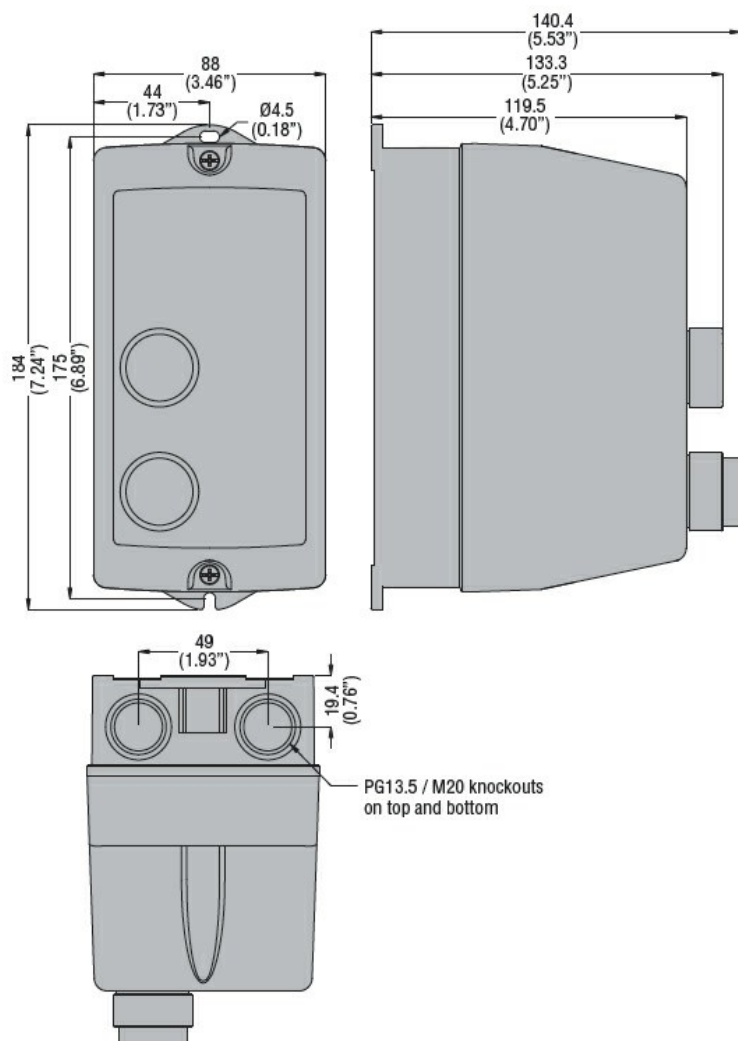

Wiring diagrams

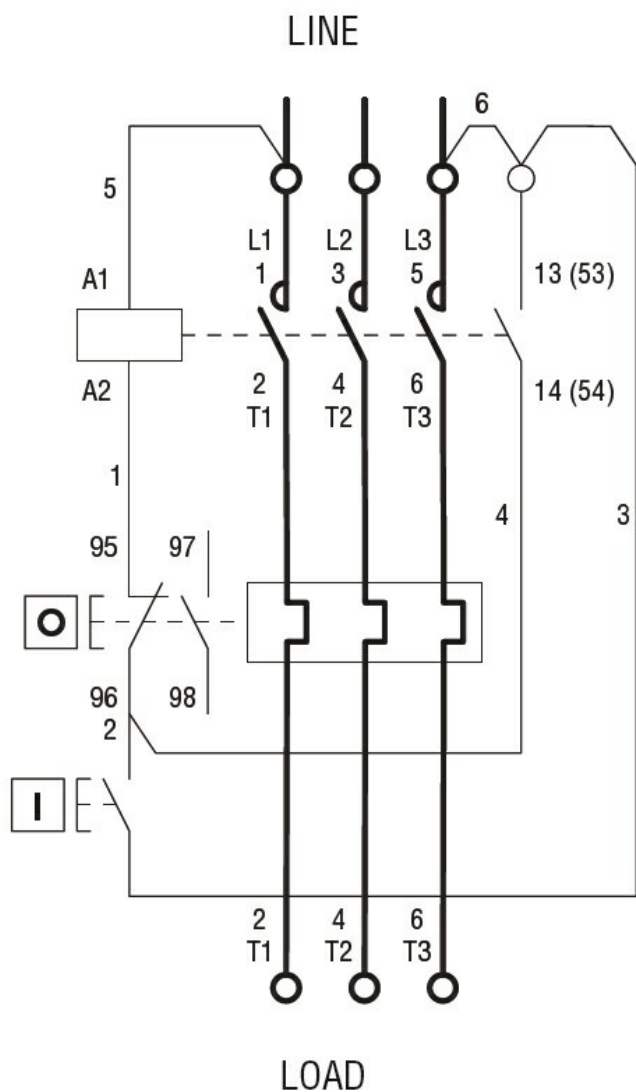

I = Start; O = Stop/Reset

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN 60947-1
IEC/EN 60947-4-1
UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices