



Product designation

Product type designation

Number of poles

Number of DIN modules

Compliance

Add-on blocks
and accessories
- 1 changeover
contact
P1X1011
1 C/O
0.5
IEC/EN/BS
60947-5-1

Electrical features

Rated impulse withstand voltage Uimp	kV	4
Rated operational voltage AC (IEC)	VAC	400
Rated current (In)	A	6
Conductivity		24V 10mA

Ambient conditions

Operating temperature

min	°C	-40
max	°C	+70

Storage temperature

min	°C	-40
max	°C	+80

Mechanical features

Operating position

normal allowable	Vertical plan Any
---------------------	----------------------

Tightening torque for terminals

min	Nm	1
max	Nm	1
min	lbin	0.7
max	lbin	0.7

Terminals tool

PH2

Conductor section


IEC

max	mm ²	1x 2.5 - 2x 1.5
-----	-----------------	-----------------


Weight

g 40

Dimensions

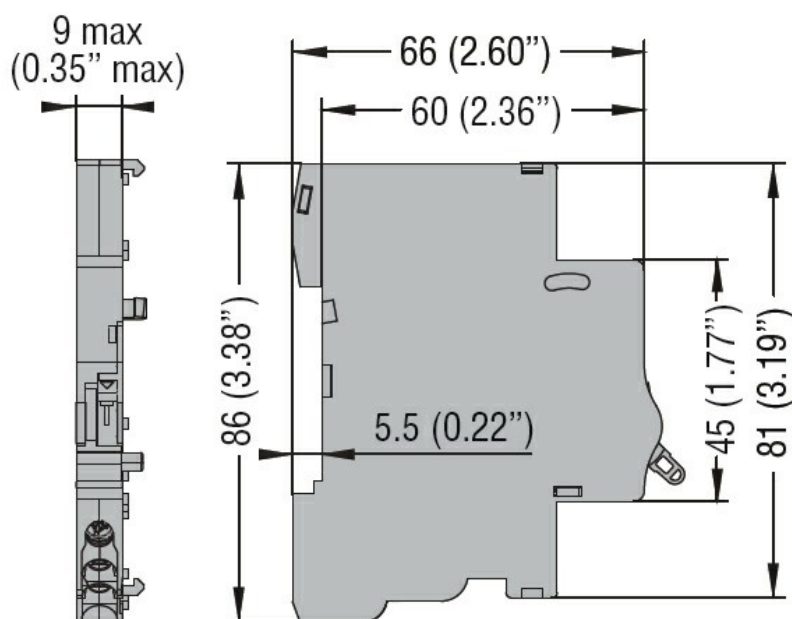

Wiring diagrams

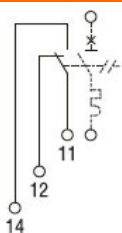

Certifications and compliance

Compliance

IEC/EN 60947-5-1. UR "UL Recognized" per Canada e USA.

Certifications

cULus
EAC

ETIM classification

ETIM 8.0

EC000041 -
Auxiliary contact
block