




Product designation	Power distribution block	
Electrical features		
Number of poles		4
Rated insulation voltage Ui	V	500
IEC Conventional free air thermal current Ith	A	100
Rated peak withstand current Ipk	kA	20
Rated short time current Icw 60s	A	4.5
Connections		
Terminal hole diameter_Option 1	mm	1x8,5mm
Conductor section connectable_Option 1	mm2	10...25
Terminal hole diameter_Option 2	mm	1x5,5mm
Conductor section connectable_Option 2	mm2	2,5...6
Terminal hole diameter_Option 3	mm	5x4,5mm
Conductor section connectable_Option 3	mm2	1,5...4
Mechanical features		
Operating position	normal allowable	Vertical plane Any
Fixing		Screw / DIN rail 35mm
Phillips		2
Weight	g	238
Resistance & Protection		
Terminals IP degree		IP20 front
Dimensions		

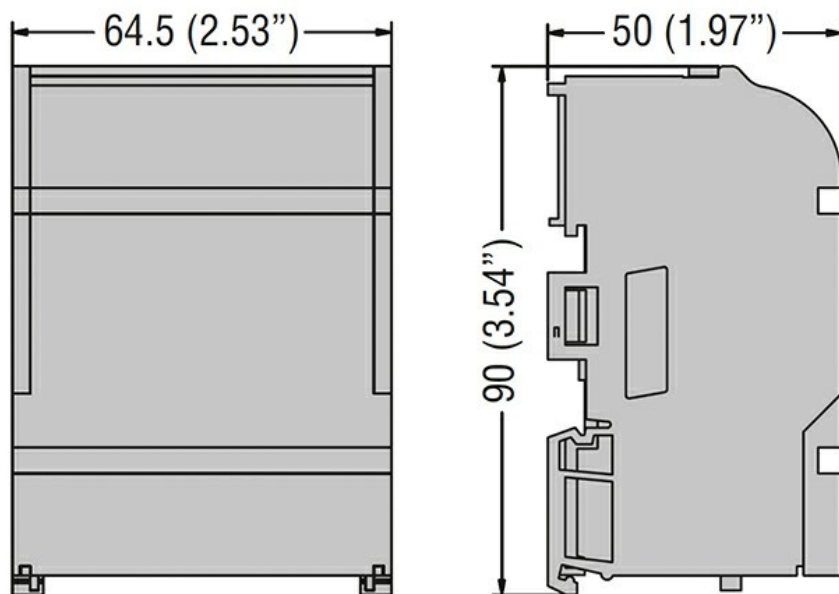

#### Certifications and compliance

##### Certifications

IEC/EN/BS 60947-7-1

##### Compliance

TÜV

#### ETIM classification

EC000066 - Power contactor, AC switching

□