



Product designation

Product type designation

Operating voltage type

Number of DIN modules

Safety  
transformer  
CTRS  
AC  
3

#### Electrical features

|                      |     |         |
|----------------------|-----|---------|
| Output power         | VA  | 15      |
| Supply voltage       | VAC | 230     |
| Rated output voltage | VAC | 12...24 |

#### Control circuit

|                                      |        |
|--------------------------------------|--------|
| Auxiliary rated supply voltage $U_s$ | 230VAC |
|--------------------------------------|--------|

#### Ambient conditions

|                       |     |    |     |
|-----------------------|-----|----|-----|
| Operating temperature | min | °C | -10 |
|                       | max | °C | +25 |
| Storage temperature   | min | °C | -40 |
|                       | max | °C | +70 |

#### Mechanical features

|                                 |     |    |   |
|---------------------------------|-----|----|---|
| Tightening torque for terminals | max | Nm | 1 |
|---------------------------------|-----|----|---|

Conductor section

Power terminal

|     |                 |     |
|-----|-----------------|-----|
| min | mm <sup>2</sup> | 0.5 |
| max | mm <sup>2</sup> | 10  |


Terminals tool

M4


Weight

g 477

#### Dimensions

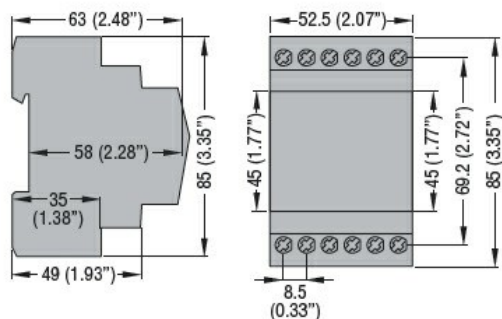

#### Wiring diagrams

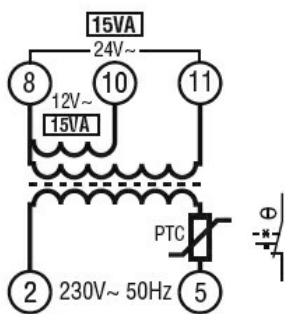

## Certifications and compliance

### Compliance

IEC/EN 61558-2-8

### ETIM classification

ETIM 8.0

EC002486 -  
One-phase  
control  
transformer