



Product designation

Electronic current  
transformers for  
EASY BRANCH  
system  
EXS3125  
Three-phase

Product type designation  
Type

#### Current inputs

Rated current (I <sub>e</sub> )	A	125
---------------------------------	---	-----

#### Current

IEC maximum (I <sub>max</sub> )	A	125
---------------------------------	---	-----

IEC rated (I <sub>ref</sub> -I <sub>b</sub> )	A	20
-----------------------------------------------	---	----

IEC start (I <sub>st</sub> )	mA	40
------------------------------	----	----

#### Insulations

Rated insulation voltage U <sub>i</sub> IEC/EN	V	600
------------------------------------------------	---	-----

#### Mechanical features

Housing type	Polyamide
--------------	-----------

Terminals type	RJ45
----------------	------

Weight	g	180
--------	---	-----

#### Ambient conditions

Temperature

Operating temperature

min	°C	-30
max	°C	+70

Storage temperature

min	°C	-30
max	°C	+80


Relative humidity	%	<80
-------------------	---	-----

Maximum Pollution degree	2
--------------------------	---

Overvoltage category	3
----------------------	---

Protection degree	IP20
-------------------	------

#### Dimensions

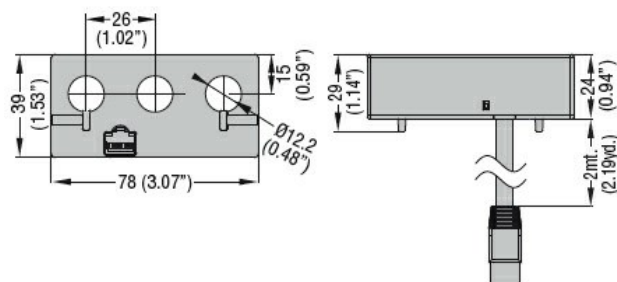

#### Certifications and compliance

Compliance

IEC/EN/BS 61000-6-2

IEC/EN/BS 61000-6-4

IEC/EN/BS 61010-1

Certificates

CE

EAC

UKCA

ETIM classification

ETIM 8.0

EC002475 -  
Current value  
transformer