



Product designation  
Product type designation

SOCKET  
HR5XS21S

#### Contact characteristics

Rated insulation voltage $U_i$ IEC/EN	V	250
Rated impulse withstand voltage $U_{imp}$	kV	4

#### Mechanical features

Socket screw tightening tool (cross / flat blade) Phillips 1/4.5mm

Conductor section

AWG/Kcmil

min	20
max	14


IEC

min	mm <sup>2</sup>	0.5
max	mm <sup>2</sup>	2.5

Fixing


On 35mm DIN  
rail

#### Dimensions

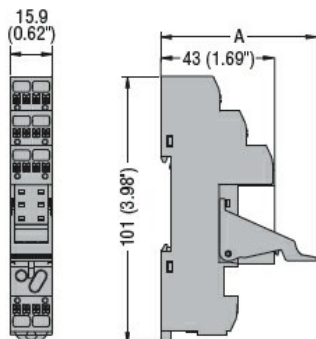

A: 60mm (2.36") with HR3X88  
70mm (2.75") with XR5X88

#### Wiring diagrams

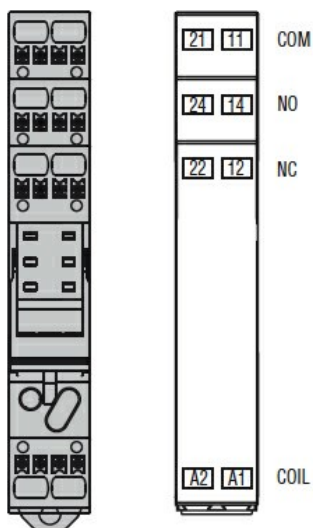

### Certifications and compliance

#### Compliance

IEC/EN 61810

#### Certificates

CSA

cURus

EAC

### ETIM classification

ETIM 8.0

EC001456 -  
Relay socket