



Mushroom head  
pushbutton,  
Latch, turn to  
release Ø  
40mm/1.6"  
LPSB664

## Product designation

## Product type designation

### General characteristics

Colour	Red
Material	Aluminium and zinc alloy for metal parts and polyamide for plastic parts
IEC degree of protection	IP66, IP67 and IP69K

### Mechanical features

Fixing	Without mounting adapter
Mounting adapter	LPXAU120M


### UL technical data

UL degree of protection	Type1, 2, 3R, 4, 4X, 12, 12K
-------------------------	------------------------------

### Ambient conditions

Temperature	Operating temperature		
	min	°C	-25
	max	°C	+70
	Storage temperature		
	min	°C	-40
	max	°C	+85

### Dimensions

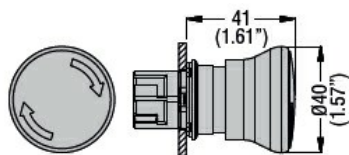

### Certifications and compliance

Compliance	CSA C22.2 n° 14
	IEC/EN/BS 60947-1
	IEC/EN/BS 60947-5-1
	UL508

### Certificates

cULus

### ETIM classification

ETIM 8.0

EC000221 -  
Front element for  
push button