



Product designation

Empty
enclosures
M3N

Product type designation

Electrical features

Maximum operating current ($\leq 440V$) A 80

Components

Contactor standard supplied BF40A, BF50A,
BF65A, BF80A,
BF94A

Thermal relay to purchase separately RF82

Mechanical features

Weight g 1800

Ambient conditions

Operating temperature

min	°C	-25
max	°C	+60



Storage temperature

min	°C	-40
max	°C	+70


Resistance & Protection

Frontal IP degree IP65

Dimensions

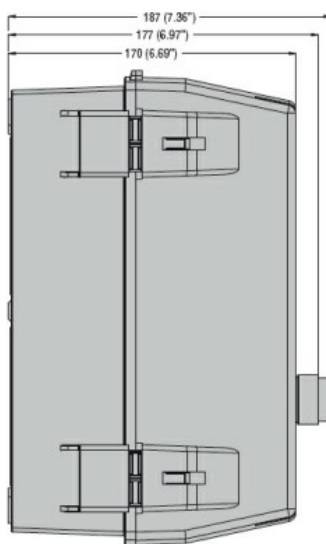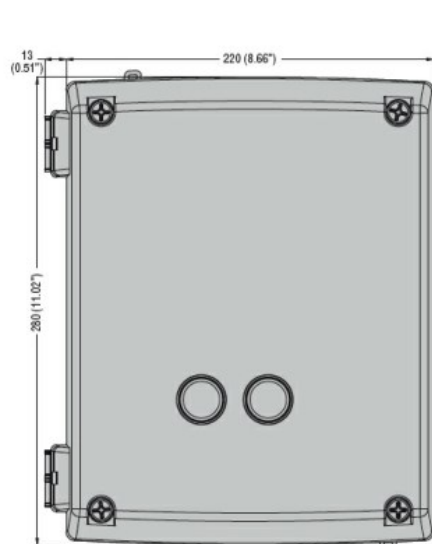

Drilling for surface fixing

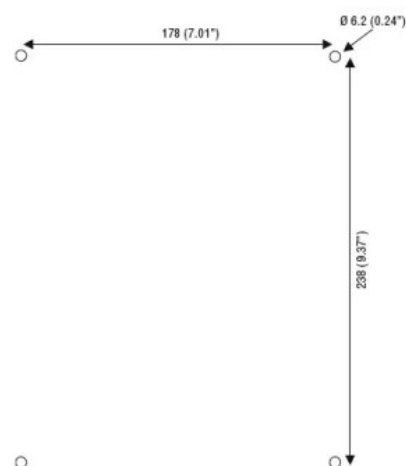

Certifications and compliance

Compliance

IEC/EN 60947-1
IEC/EN 60947-4-1

Certificates

cULus

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices