



Product designation

Toroidal current transformers


Control circuit

Toroidal transformer


Diam. 60  
mm/2.36"

Dimensions


RT35 - RT60 - RT80 - RT110 - RX10

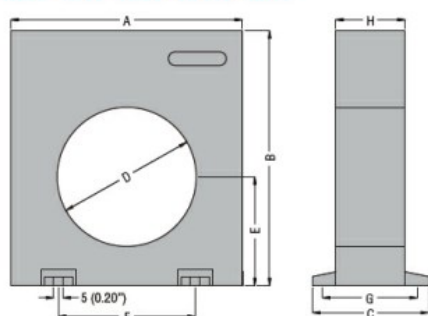

RT210 - RTA210

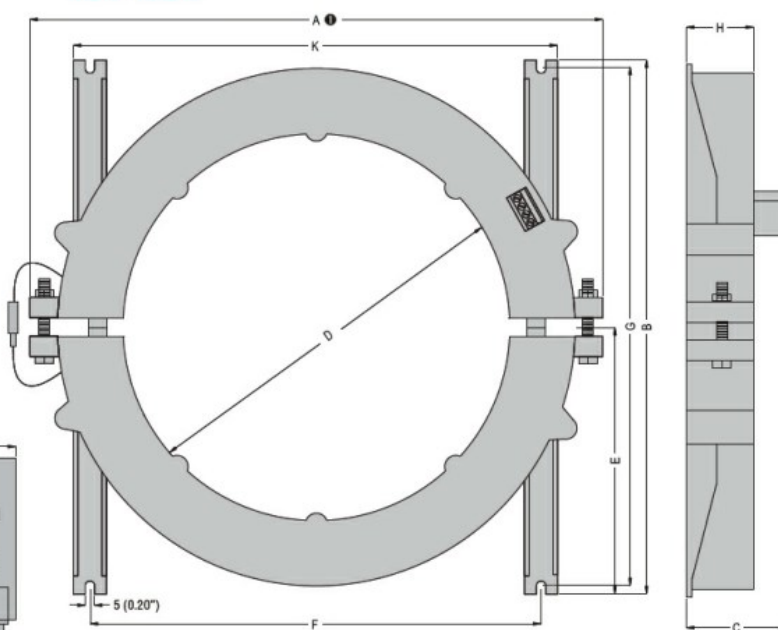

RTA110

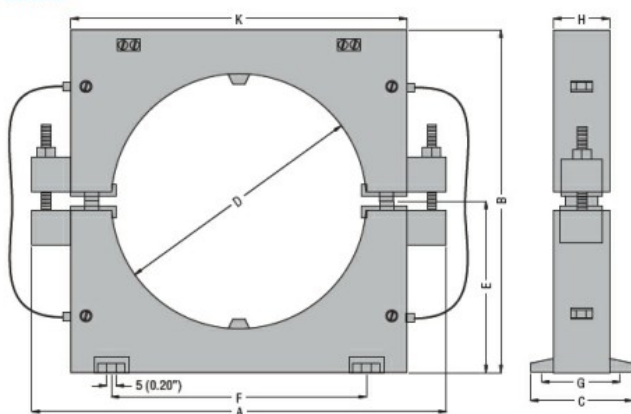

| TYPE   | A            | B            | C          | D           | E           | F           | G            | H          | K            |
|--------|--------------|--------------|------------|-------------|-------------|-------------|--------------|------------|--------------|
| RT35   | 100 (3.94")  | 110 (4.33")  | 50 (1.97") | 35 (1.38")  | 47 (1.85")  | 60 (2.36")  | 43 (1.69")   | 30 (1.18") | —            |
| RT60   | 100 (3.94")  | 110 (4.33")  | 50 (1.97") | 60 (2.36")  | 47 (1.85")  | 60 (2.36")  | 43 (1.69")   | 30 (1.18") | —            |
| RT80   | 150 (5.90")  | 160 (6.30")  | 50 (1.97") | 80 (3.15")  | 70 (2.75")  | 110 (4.33") | 43 (1.69")   | 30 (1.18") | —            |
| RT110  | 150 (5.90")  | 160 (6.30")  | 50 (1.97") | 110 (4.33") | 70 (2.75")  | 110 (4.33") | 43 (1.69")   | 30 (1.18") | —            |
| RT210  | 310 (12.20") | 290 (11.41") | 54 (2.12") | 210 (8.27") | 145 (5.71") | 240 (9.45") | 280 (11.02") | 36 (1.42") | 258 (10.16") |
| RTA110 | 180 (7.09")  | 150 (5.90")  | 45 (1.77") | 110 (4.33") | 75 (2.95")  | 110 (4.33") | 38 (1.50")   | 25 (0.98") | 145 (5.71")  |
| RTA210 | 310 (12.20") | 290 (11.41") | 54 (2.12") | 210 (8.27") | 145 (5.71") | 240 (9.45") | 280 (11.02") | 36 (1.42") | 258 (10.16") |
| RX10   | 100 (3.94")  | 110 (4.33")  | 50 (1.97") | —           | —           | 60 (2.36")  | 43 (1.69")   | 30 (1.18") | —            |

Certifications and compliance

Compliant with standards

IEC/EN 60947-2

Certificates

EAC

ETIM classification

ETIM 8.0

EC002048 -  
Current  
transformer