

KOMPLETNI POKRETAČ ZVIJEZDA TROKUT, OTVORENE IZVEDBE, VRIJEME ZAleta DO 12 SEKUNDI I MAKSIMALNE UČESTALOSTI OD 30 SKLAPANJA/SAT, MAX IEC POGONSKA STRUJA 43A. NAPON SVITKA 230VAC 50/60HZ



Product designation	Star-delta starter
Product type designation	BFA026

Electrical features

Maximum operating current ($\leq 440V$)	A	43
---	---	----

Components

Contactor standard supplied	BF2600A / BF2600A / BF1810A	
Thermal relay standard supplied	No	
Thermal relay to purchase separately	RF38	
Auxiliary contact standard supplied	BFX1020 / BFX1011 / BFX1011	

Contact characteristics

IEC standard motor powers	230V	kW	11
	400V	kW	22
	440V	kW	22
	500V	kW	25



Mechanical features

Weight	g	1800
--------	---	------

Dimensions

STARTER TYPE	A	B
BFA009 70	130.5 (5.14")	109.5 (4.31")
BFA012 70	130.5 (5.14")	109.5 (4.31")
BFA018 70	130.5 (5.14")	109.5 (4.31")
BFA025 70	130.5 (5.14")	109.5 (4.31")
BFA026 70	135 (5.14")	119 (4.68")
BFA032 70	135 (5.14")	119 (4.68")
BFA038 70	135 (5.14")	119 (4.68")
BFA050 70	173 (6.81")	142 (5.59")
BFA065 70	173 (6.81")	142 (5.59")
BFA080 70	183 (7.20")	142 (5.59")

Wiring diagrams

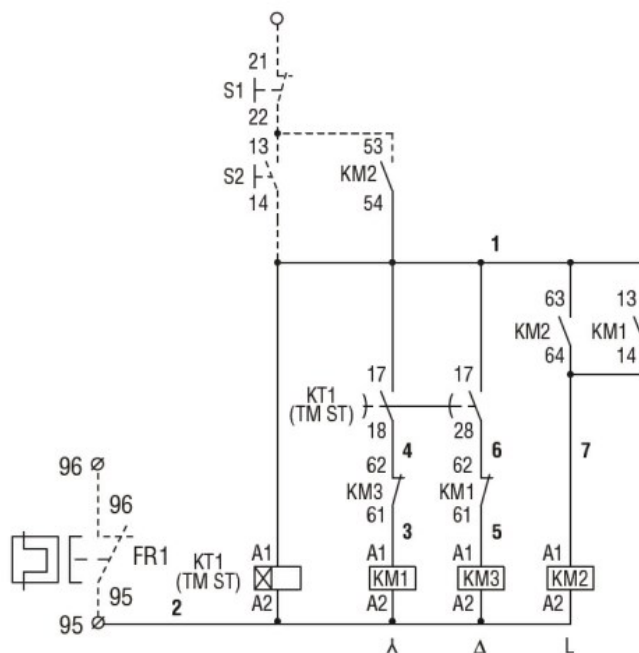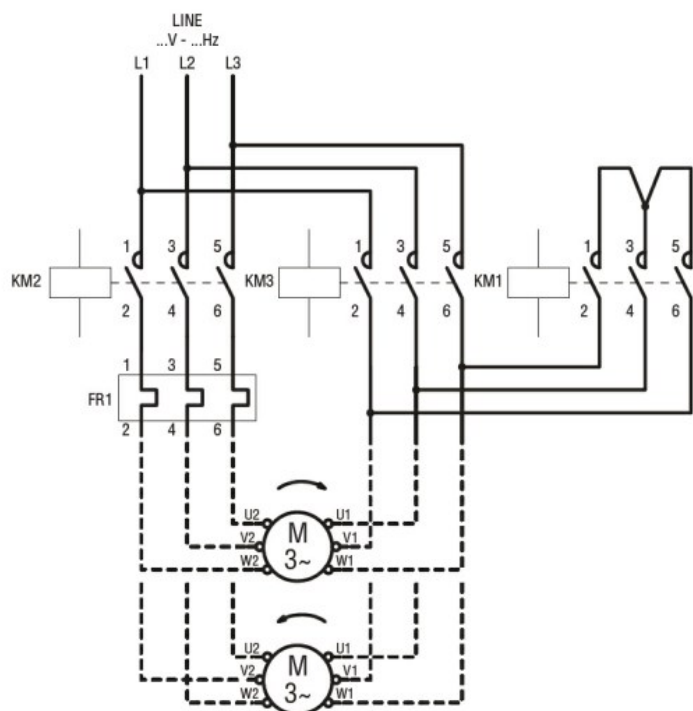

Certifications and compliance

Compliance

IEC/EN 60947-1

IEC/EN 60947-4-9

Certificates

/

ETIM classification

ETIM 8.0

EC001037 -
Motor
starter/Motor
starter
combination