




|                                   |                         |     |     |
|-----------------------------------|-------------------------|-----|-----|
| Product designation               | Empty enclosures        |     |     |
| Product type designation          | M24N                    |     |     |
| Electrical features               |                         |     |     |
| Maximum operating current (≤440V) | A                       | 38  |     |
| Components                        |                         |     |     |
| Contactor standard supplied       | BG.../BF09A...<br>BF25A |     |     |
| Mechanical features               |                         |     |     |
| Weight                            | g                       | 625 |     |
| Ambient conditions                |                         |     |     |
| Operating temperature             | min                     | °C  | -25 |
|                                   | max                     | °C  | +60 |
| Storage temperature               | min                     | °C  | -40 |
|                                   | max                     | °C  | +70 |
| Resistance & Protection           |                         |     |     |
| Frontal IP degree                 | IP65                    |     |     |
| Dimensions                        |                         |     |     |

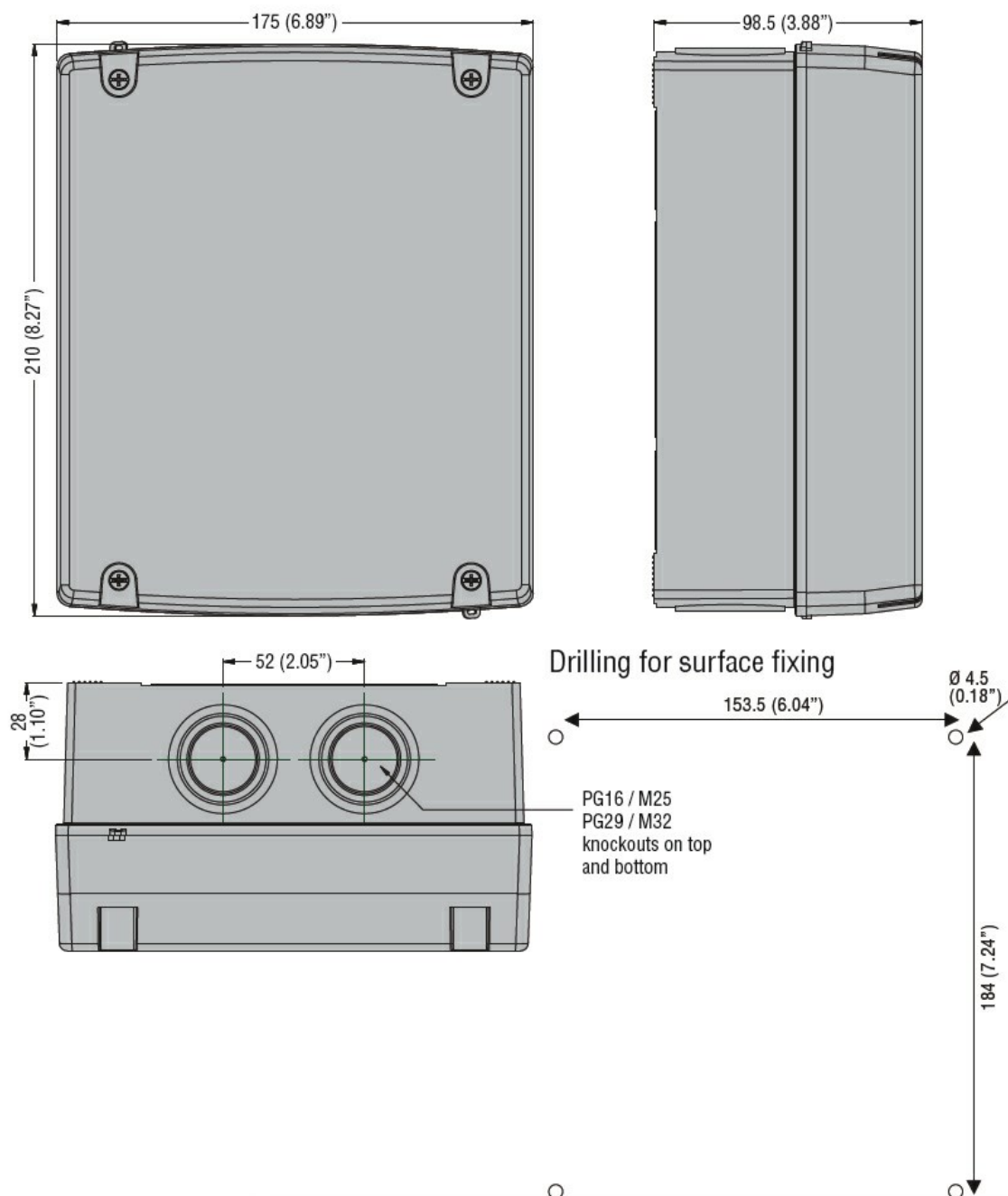

## Certifications and compliance

### Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-4-1

UL508

### Certificates

cULus

## ETIM classification

ETIM 8.0

EC000200 -  
Enclosure for  
control circuit  
devices