



GLC0320...630... - GLC0400...UL

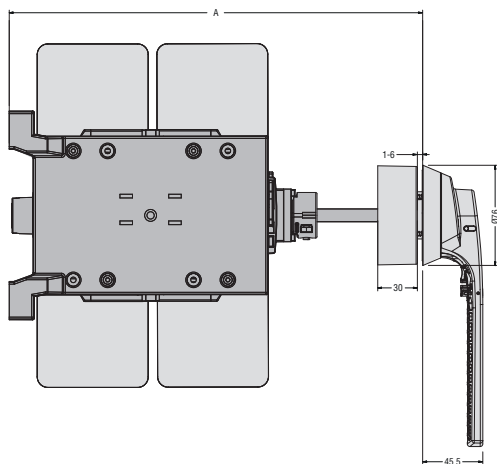

GLX7...S10	B [mm]	A [mm]	
		min	max
GLX7150S10	150	267...	337
GLX7200S10	200	267...	387
GLX7300S10	300	267...	487
GLX7400S10	400	267...	587
GLX7500S10	500	267...	687

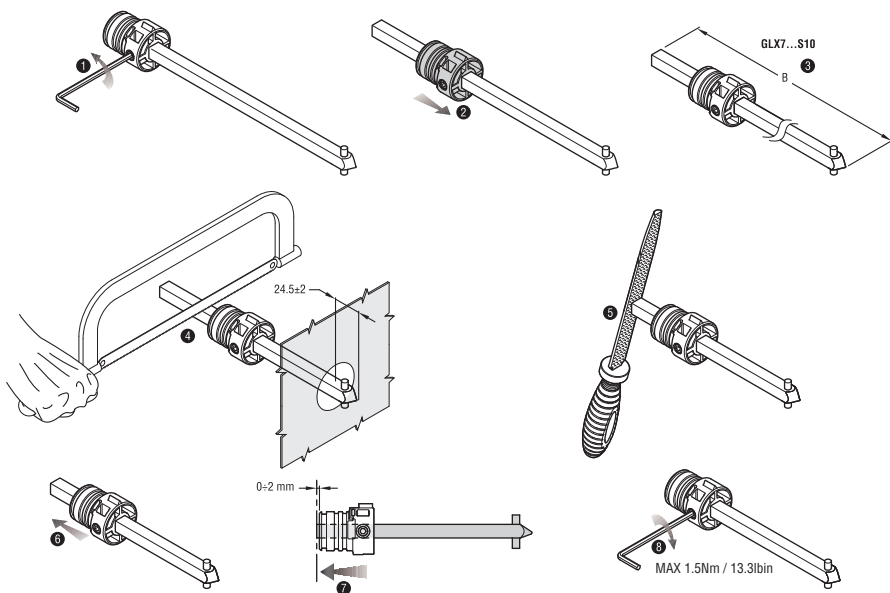

GLX62CB

