




Product designation	Electronic current transformers for EASY BRANCH system		
Product type designation	EXS1032		
Type	single-phase		
Current inputs			
Rated current (Ie)	A	32	
Current			
IEC maximum (Imax)	A	32	
IEC rated (Iref-Ib)	A	5	
IEC start (Ist)	mA	10	
Insulations			
Rated insulation voltage Ui IEC/EN	V	600	
Mechanical features			
Housing type	Polyamide		
Terminals type	RJ45		
Weight	g	120	
Ambient conditions			
Temperature	Operating temperature		
	min	°C	-30
	max	°C	+70
	Storage temperature		
	min	°C	-30
	max	°C	+80
Relative humidity	%		<80
Maximum Pollution degree	2		
Overvoltage category	3		
Protection degree	IP20		
Dimensions			

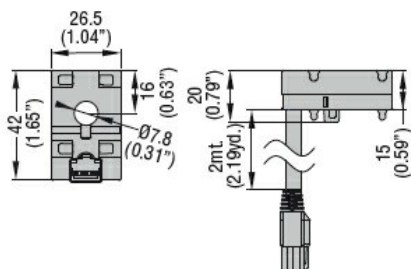

Certifications and compliance	
Compliance	
	IEC/EN/BS 61000-6-2
	IEC/EN/BS 61000-6-4
	IEC/EN/BS 61010-1
Certificates	

CE

EAC

UKCA

ETIM classification

ETIM 8.0

EC002475 -
Current value
transformer