





Product designation			Empty enclosures
Product type designation			M0RA
Electrical features			
Maximum operating current (≤440V)	A	12	
Components			
Contactor standard supplied			BG06, BG09, BG12
Thermal relay to purchase separately			RF9
Mechanical features			
Weight	g	445	
Ambient conditions			
Operating temperature	min	°C	-25
	max	°C	+60
Storage temperature	min	°C	-40
	max	°C	+70
Resistance & Protection			
Frontal IP degree			IP65
Dimensions			

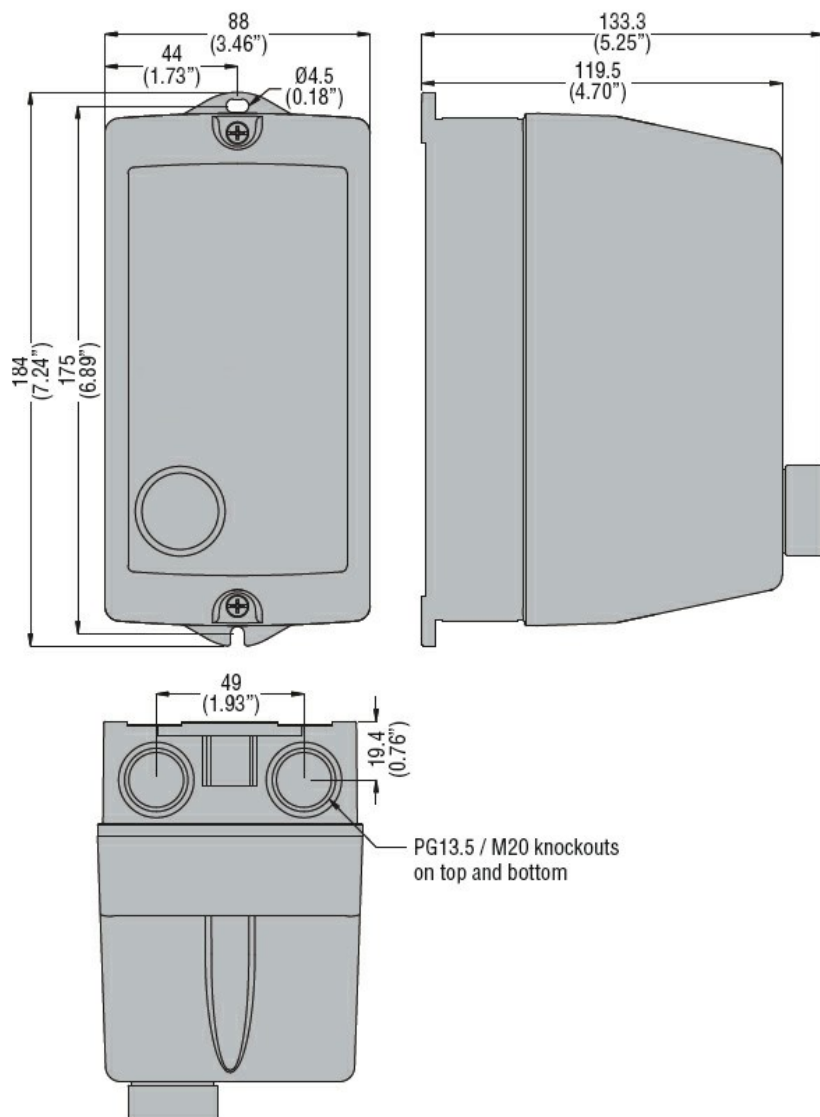

Wiring diagrams

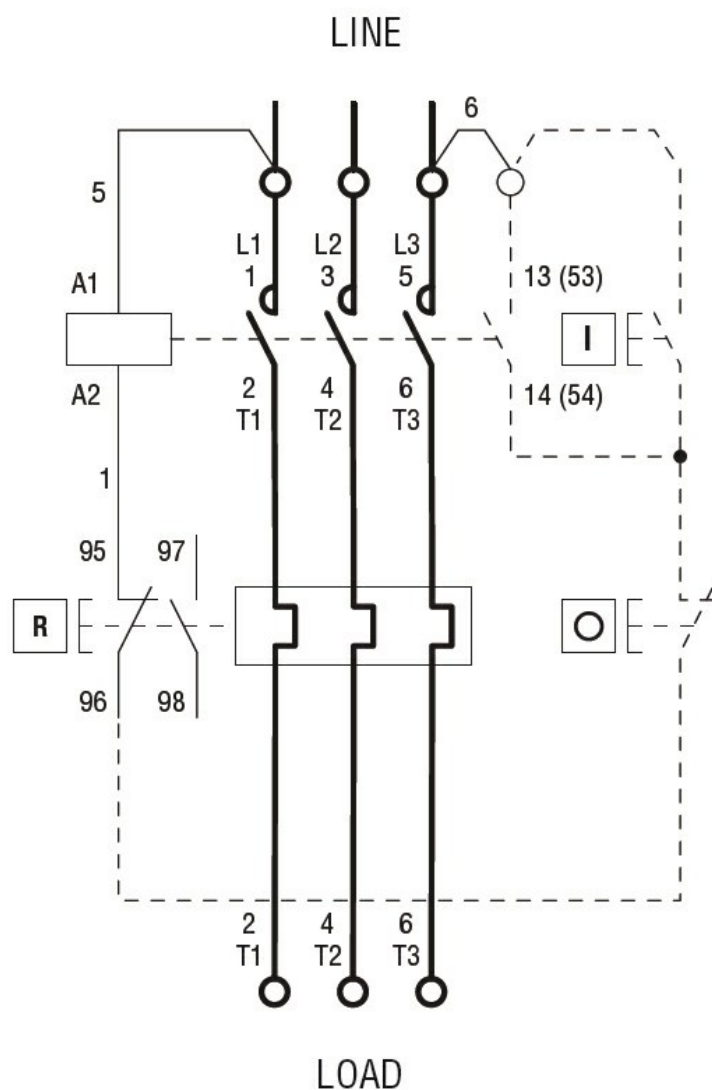

R = Reset; I = Start; O = Stop

Certifications and compliance

Compliance

CSA C22.2 n° 14
IEC/EN 60947-1
IEC/EN 60947-4-1
UL508

Certificates

cULus

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices