



Product designation

Empty  
enclosures

Product type designation

M25N

#### Electrical features

Maximum operating current ( $\leq 440V$ )	A	38
---	---	----

#### Components

Contactor standard supplied	BF38A
-----------------------------	-------

Thermal relay to purchase separately	RF38
--------------------------------------	------

#### Mechanical features

Weight	g	940
--------	---	-----

#### Ambient conditions

Operating temperature

min	°C	-25
max	°C	+60


Storage temperature

min	°C	-40
max	°C	+70

#### Resistance & Protection

Frontal IP degree	IP65
-------------------	------

#### Dimensions

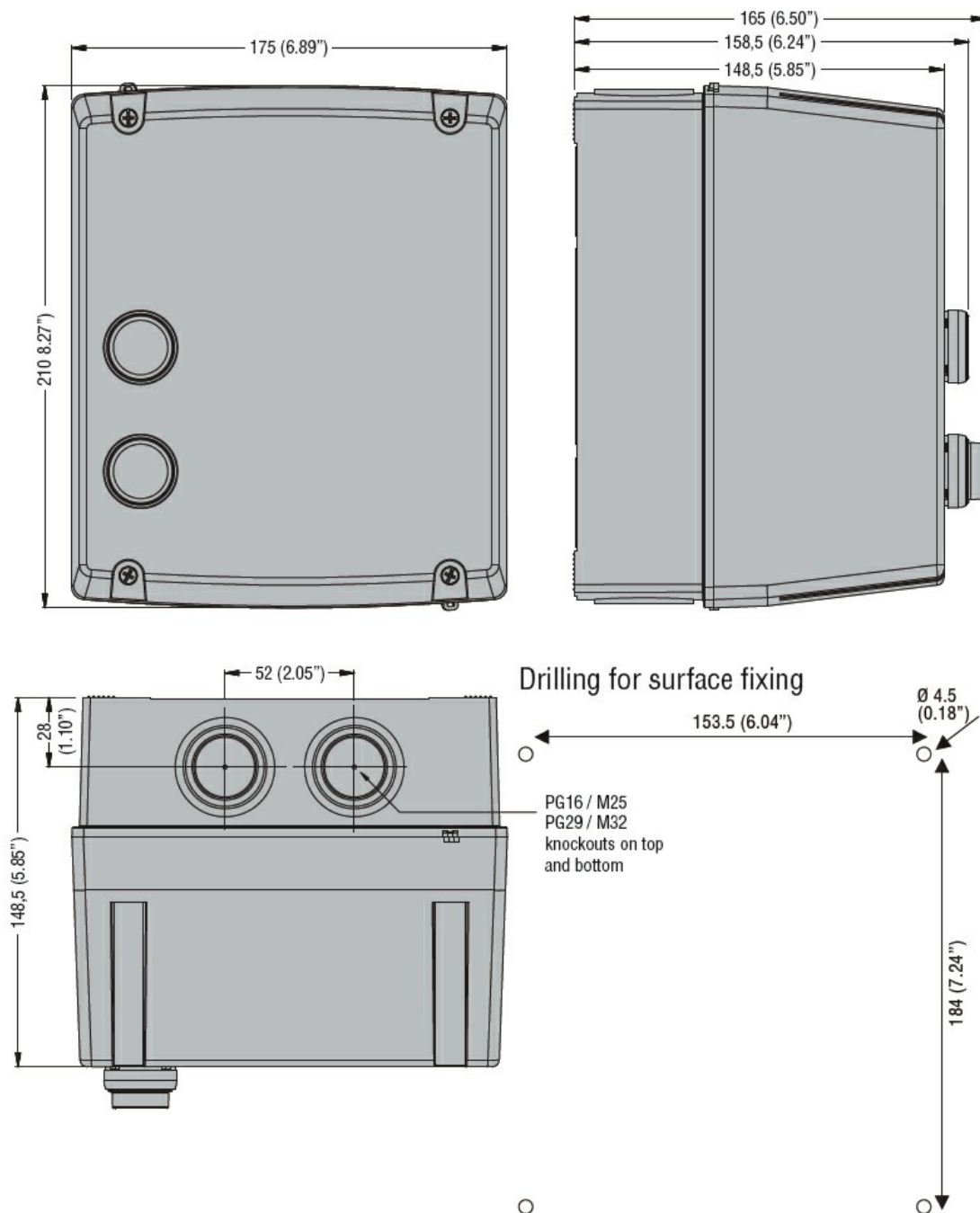

## Certifications and compliance

### Compliance

CSA C22.2 n° 14  
IEC/EN 60947-1  
IEC/EN 60947-4-1  
UL508

### Certificates

cULus

## ETIM classification

ETIM 8.0

EC000200 -  
Enclosure for  
control circuit  
devices