




Product designation	Empty enclosures		
Product type designation	M2N		
Electrical features			
Maximum operating current (≤440V)	A	32	
Components			
Contactor standard supplied	BF25A, BF26A, BF32A		
Thermal relay to purchase separately	RF38		
Mechanical features			
Weight	g	640	
Ambient conditions			
Operating temperature	min	°C	-25
	max	°C	+60
Storage temperature	min	°C	-40
	max	°C	+70
Resistance & Protection			
Frontal IP degree	IP65		
Dimensions			

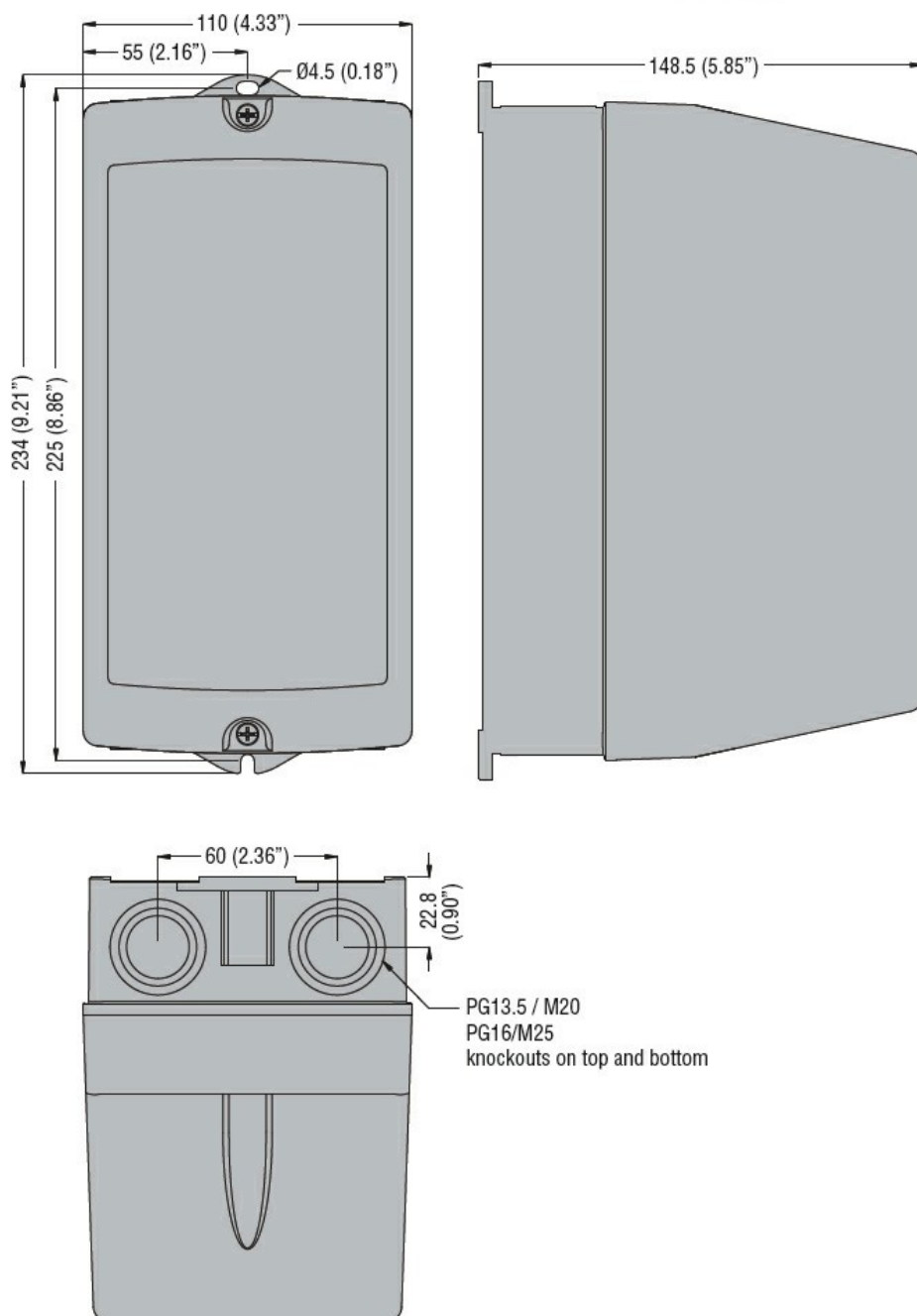

## Certifications and compliance

### Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-4-1

UL508

### Certificates

cULus

## ETIM classification

ETIM 8.0

EC000200 -  
Enclosure for  
control circuit  
devices