

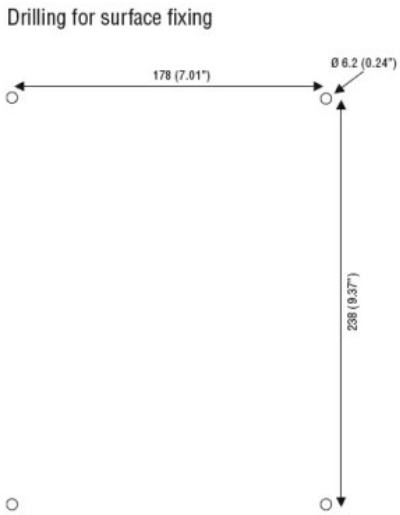


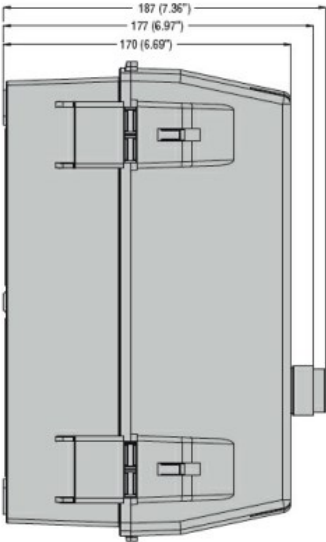

Product designation	Empty enclosures		
Product type designation	M3N		
Electrical features			
Maximum operating current (≤440V)	A	80	
Components			
Contactor standard supplied	BF40A, BF50A, BF65A, BF80A, BF94A		
Thermal relay to purchase separately	RF82		
Mechanical features			
Weight	g	1800	
Ambient conditions			
Operating temperature	min	°C	-25
	max	°C	+60
Storage temperature	min	°C	-40
	max	°C	+70
Resistance & Protection			
Frontal IP degree	IP65		
Dimensions			

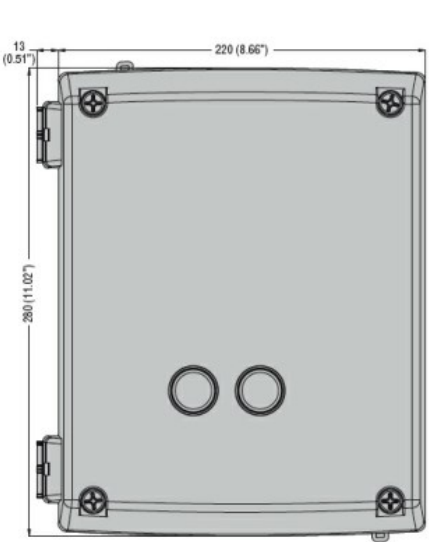

Certifications and compliance	
Compliance	IEC/EN 60947-1
	IEC/EN 60947-4-1
Certificates	cULus
ETIM classification	

ETIM 8.0

EC000200 -  
Enclosure for  
control circuit  
devices