



Product designation	Probe
Product type designation	SCM
Connections	


Terminals type	Threaded rod with nut
----------------	-----------------------

Ambient conditions	
Temperature	

Operating temperature	max	°C	+100
Maximum operating pressure		bar	10

Housing		
Weight	g	115

Dimensions	
-------------------	--

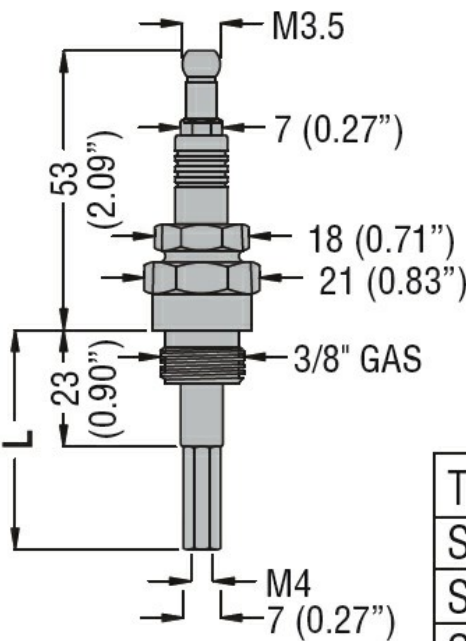

TYPE	L
SCM04	43 (1.69'')
SCM50	500 (19.68'')
SCM100	1000 (39.37'')

Certifications and compliance	
Compliance	/

Certificates	EAC
--------------	-----

ETIM classification	
ETIM 8.0	EC010106 - Liquid level sensor