



Enclosed  
automatic  
transfer switches  
ATS  
ATP

Product designation

Product type designation

#### Voltage inputs

Maximum rated voltage Ue	400
--------------------------	-----

Frequency range	Hz	45...65
-----------------	----	---------

#### Current inputs

Rated current (Ie)	A	45 (AC1)
--------------------	---	----------

#### Digital inputs

Number of digital input	Nr.	6
-------------------------	-----	---

#### Relay outputs

Number of relay output	Nr.	7
------------------------	-----	---

Contact arrangement

6 with 1NO -  
SPST 1 with  
NO/NC - SPDT

#### Insulations

Voltage inputs

Rated insulation voltage Ui	VAC	400
Rated impulse withstand voltage Uimp	kV	4

#### Ambient conditions

Maximum Pollution degree	2
--------------------------	---

Overvoltage category	3
----------------------	---


#### Housing

Material	Metallic
----------	----------


Degree of protection	IP65
----------------------	------

Dimensions (W x H x D)	mm	500x400x200
------------------------	----	-------------

#### Dimensions

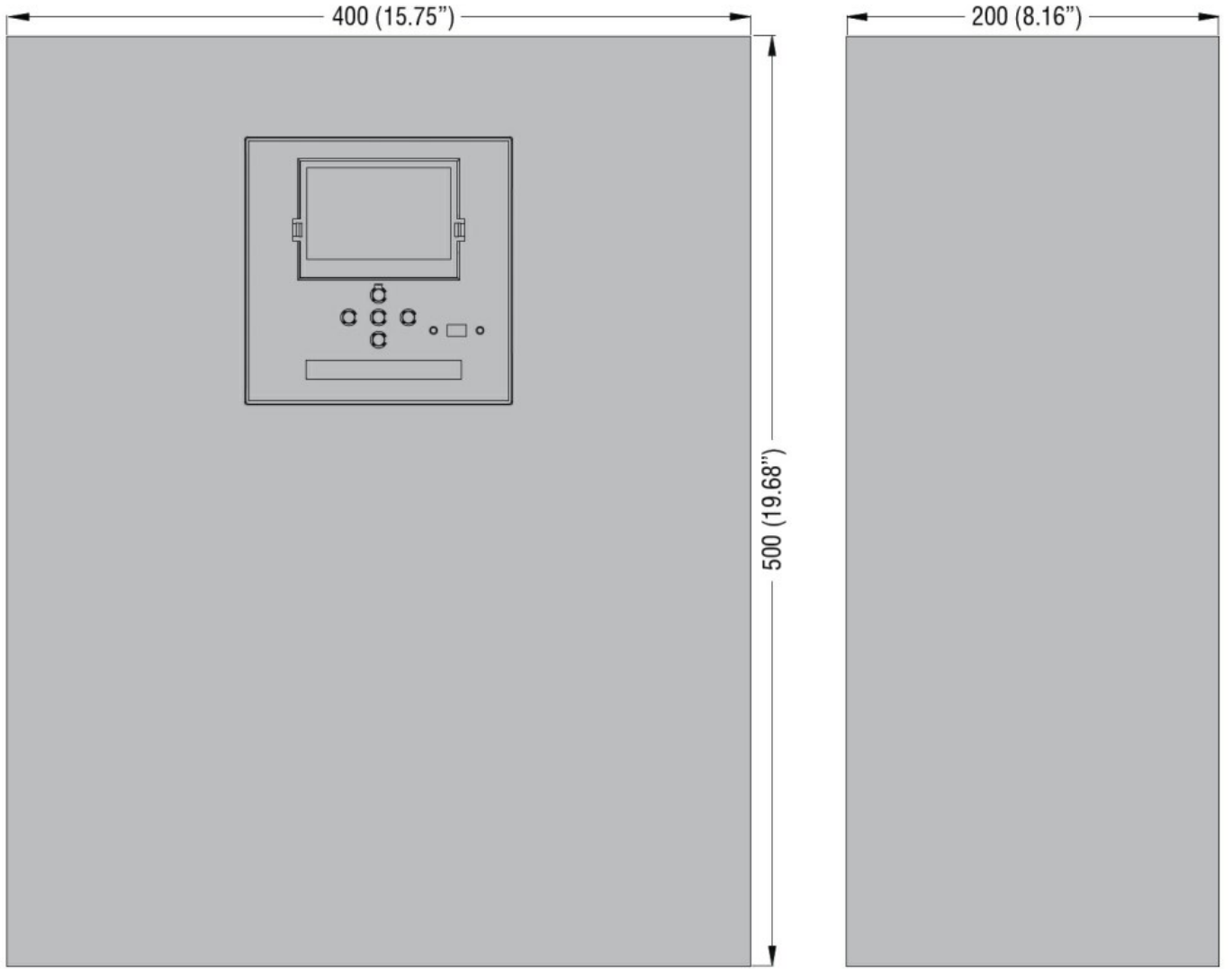

## Wiring diagrams

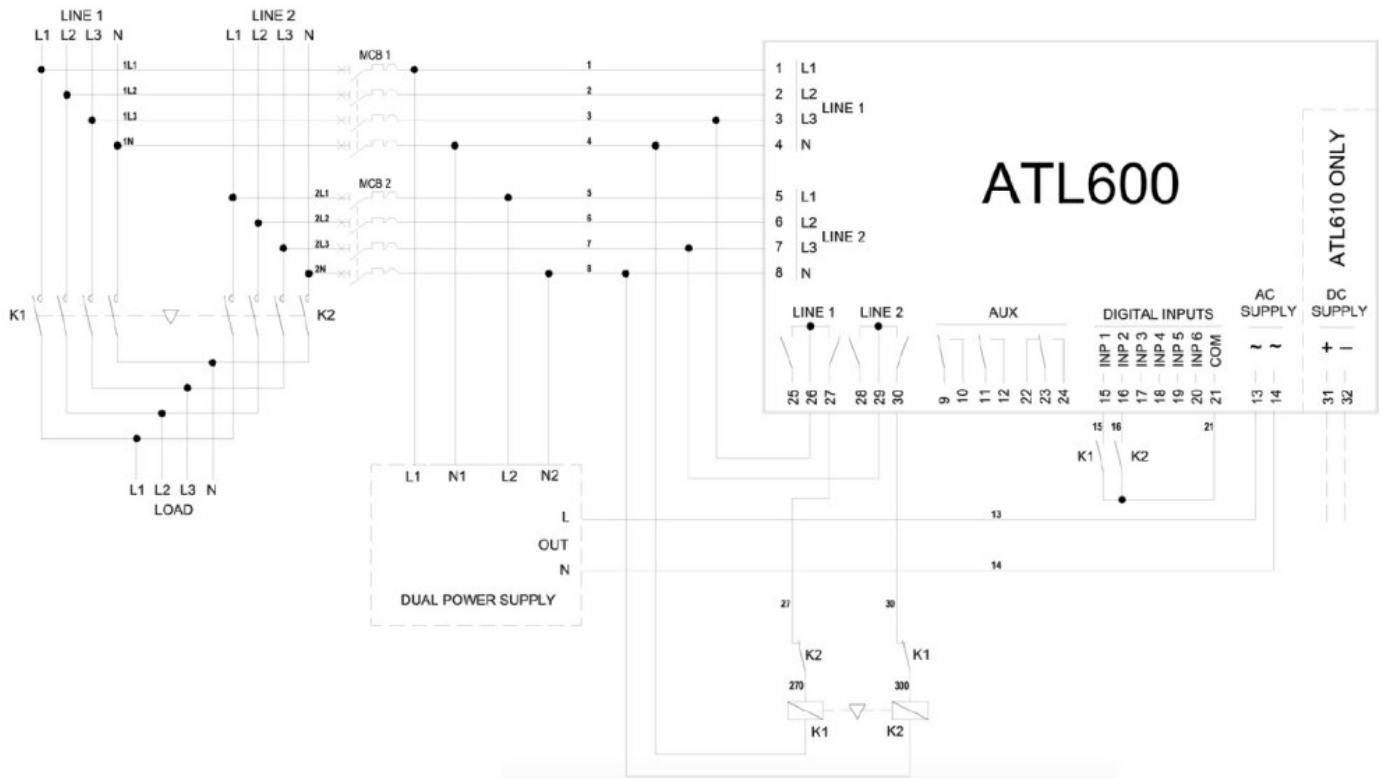

## Certifications and compliance

### Compliance

IEC 61439-2