



Product designation

Product type designation

Operating voltage type

Number of DIN modules

Safety
transformer
CTRS
AC
3

Electrical features

Output power	VA	15
Supply voltage	VAC	230
Rated output voltage	VAC	12...24

Control circuit

Auxiliary rated supply voltage U_s	230VAC
--------------------------------------	--------

Ambient conditions

Operating temperature	min	°C	-10
	max	°C	+25
Storage temperature	min	°C	-40
	max	°C	+70

Mechanical features

Tightening torque for terminals	max	Nm	1
---------------------------------	-----	----	---

Conductor section

Power terminal

min	mm ²	0.5
max	mm ²	10


Terminals tool

M4


Weight

g 477

Dimensions

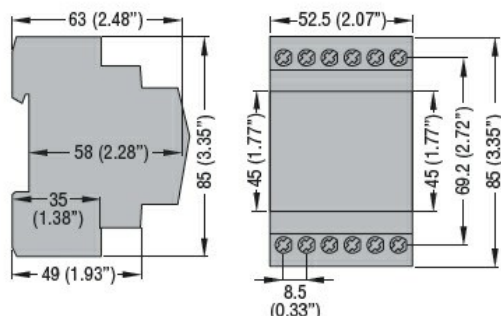

Wiring diagrams

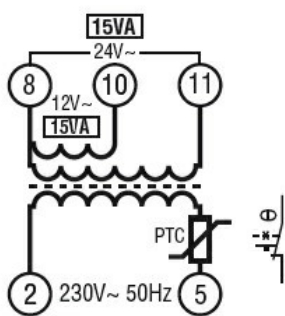

Certifications and compliance

Compliance

IEC/EN 61558-2-8

ETIM classification

ETIM 8.0

EC002486 -
One-phase
control
transformer