



Product designation

Empty  
enclosures  
M3PA

Product type designation

### Electrical features

Maximum operating current ( $\leq 440V$ ) A 80

### Components

Contactor standard supplied BF40A, BF50A,  
BF65A, BF80A,  
BF94A

Thermal relay to purchase separately RF82

### Mechanical features

Weight g 1900

### Ambient conditions

Operating temperature

min	°C	-25
max	°C	+60



Storage temperature

min	°C	-40
max	°C	+70


### Resistance & Protection

Frontal IP degree IP65


### Dimensions

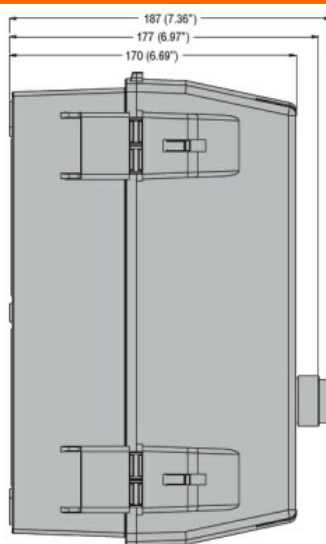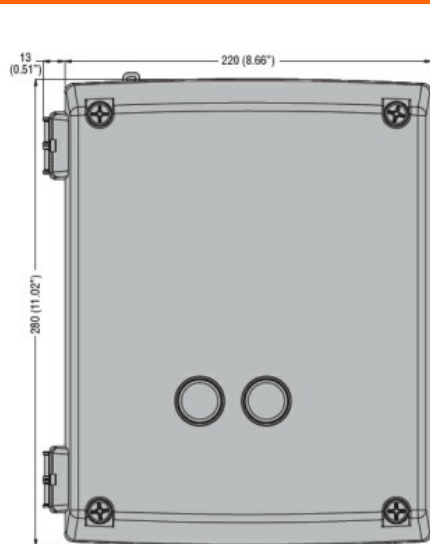

Drilling for surface fixing

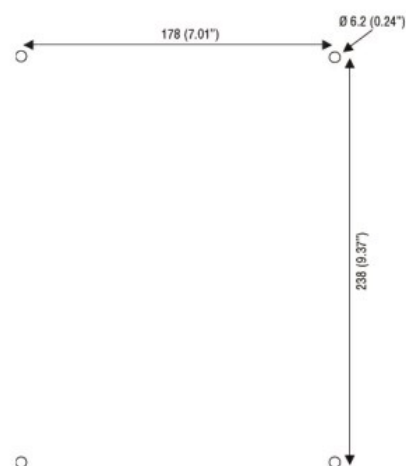

### Wiring diagrams

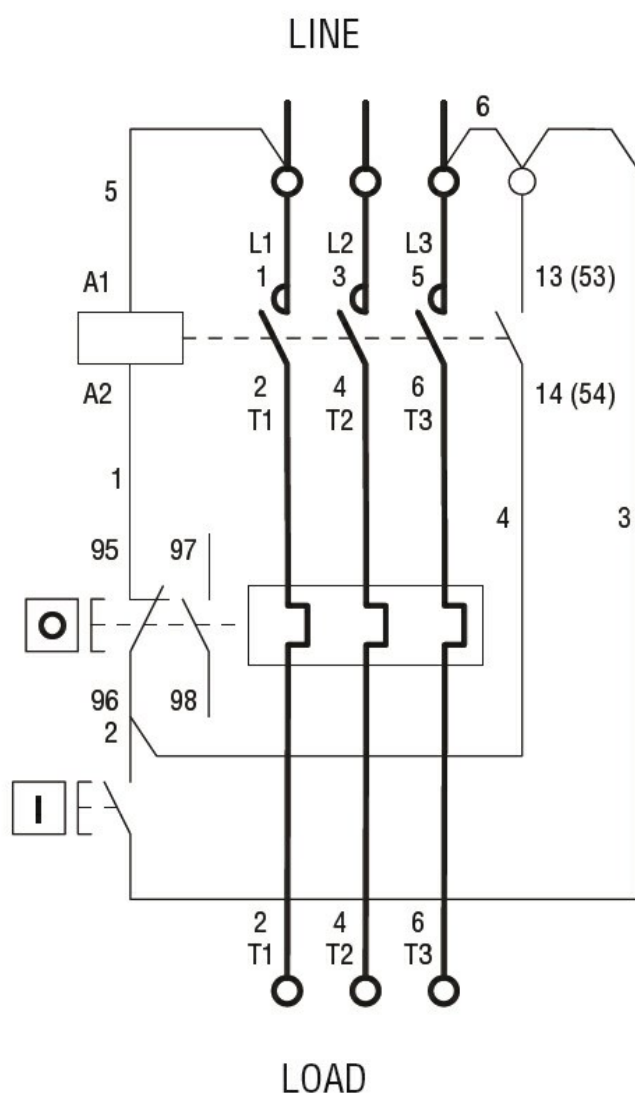

I = Start; O = Stop/Reset

#### Certifications and compliance

##### Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-4-1

UL508

##### Certificates

cULus

#### ETIM classification

ETIM 8.0

EC000200 -  
Enclosure for  
control circuit  
devices