



Product designation
Product type designation

Probe
SCM

Connections

Terminals type

Threaded rod
with nut

Ambient conditions

Temperature

Operating temperature

max °C +100

Maximum operating pressure


bar 10

Housing

Weight

g 60

Dimensions

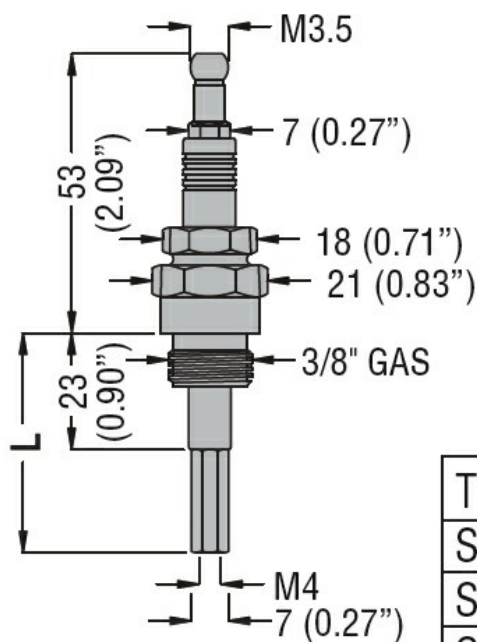

| TYPE | L |
|--------|----------------|
| SCM04 | 43 (1.69'') |
| SCM50 | 500 (19.68'') |
| SCM100 | 1000 (39.37'') |

Certifications and compliance

Compliance

/

Certificates

EAC

ETIM classification

ETIM 8.0

EC010106 -
Liquid level
sensor