



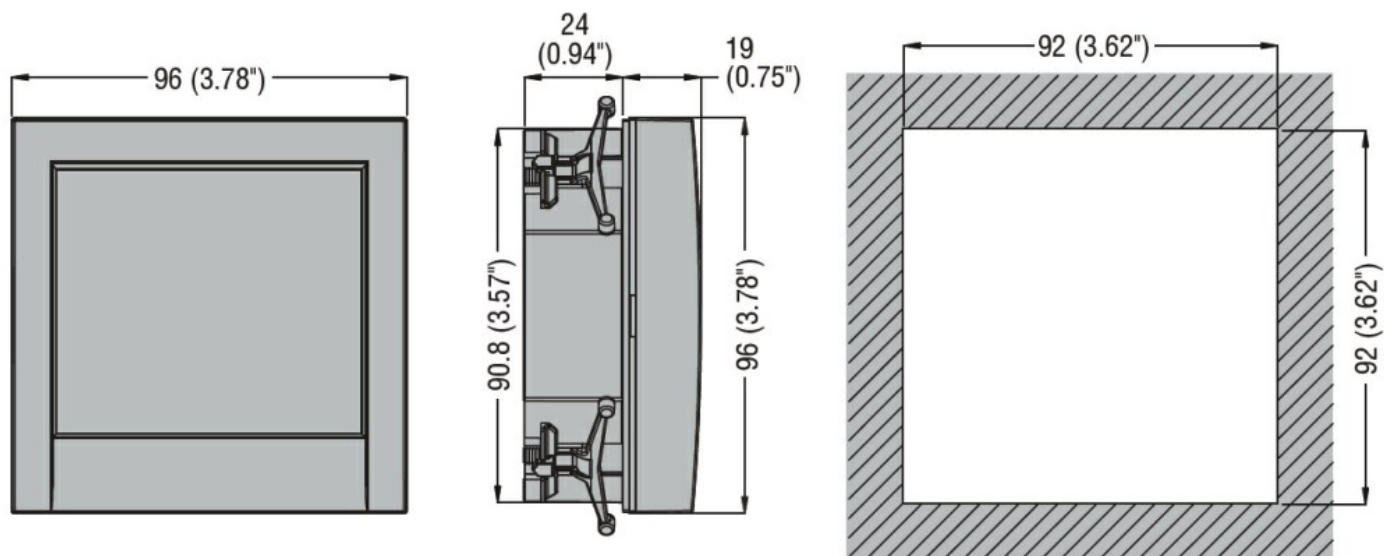

Product designation			Remote display unit
Product type designation			EXCRDU1
General characteristics			
Description			Remote display unit, graphic LCD, touch screen 128x112 pixels, IP65 protection. Compatible with ADXL... soft starter and VLB3... variable speed drives
Functions			Remote display unit
Rated power supply voltage			Auxiliary supply 100...240VAC/12...24VDC
Interface			
RS485 communication			Yes
Mechanical features			
Conductor cross section			
	min	mm²	0.2
	Max	mm²	2.5
	min	AWG	24 / 18 for UL/CSA
	Max	AWG	12
Tightening torque (Max)			
		Nm	0.56
		lbin	4.5
Dimensions			

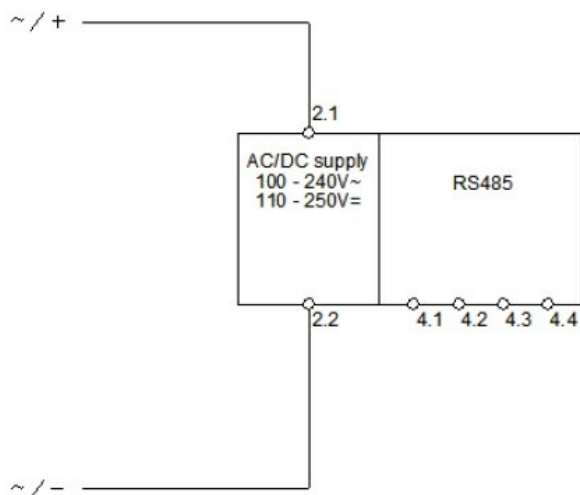

Wiring diagrams



Certifications and compliance

Compliance

C22.2-n°14-95

IEC/EN 61000-6-2

IEC/EN 61000-6-4

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC002498 -
Accessories/spare
parts for low-
voltage switch
technology