



Product designation

SOCKET

Product type designation

HR5XS22

### Contact characteristics

Rated insulation voltage $U_i$ IEC/EN	V	250
Rated impulse withstand voltage $U_{imp}$	kV	4

### Mechanical features

Socket screw tightening tool (cross / flat blade)	Phillips 1/4.5mm
---	------------------

Conductor section

AWG/Kcmil

min	20
max	14


IEC

min	mm <sup>2</sup>	0.5
max	mm <sup>2</sup>	2.5

Fixing


On 35mm DIN  
rail and with  
screw

### Dimensions

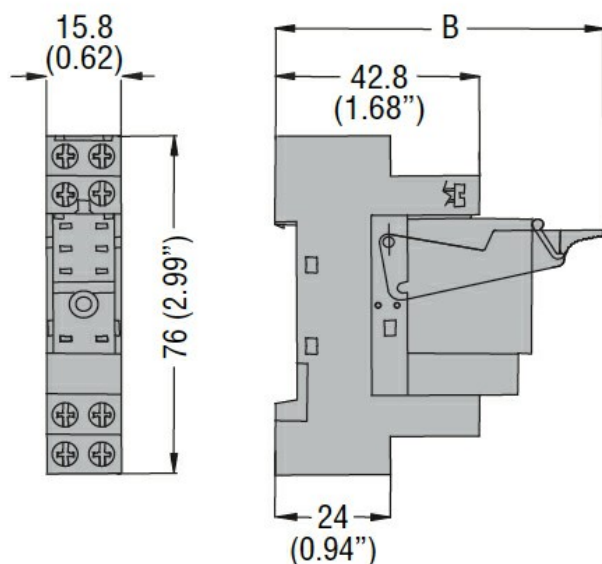

B: 72.5mm (2.85") con HR3X88  
82.5mm (3.25) con XR5X88

### Wiring diagrams

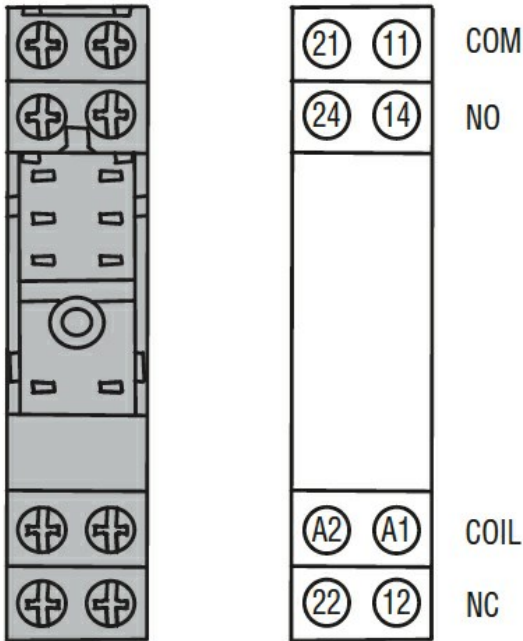

Certifications and compliance

Compliance

IEC/EN 61810

Certificates

- CSA
- cULus
- cURus
- EAC

ETIM classification

ETIM 8.0 EC001456 - Relay socket